


TECHSPEC® 40 x 40mm Enhanced Aluminum, λ/20 Mirror

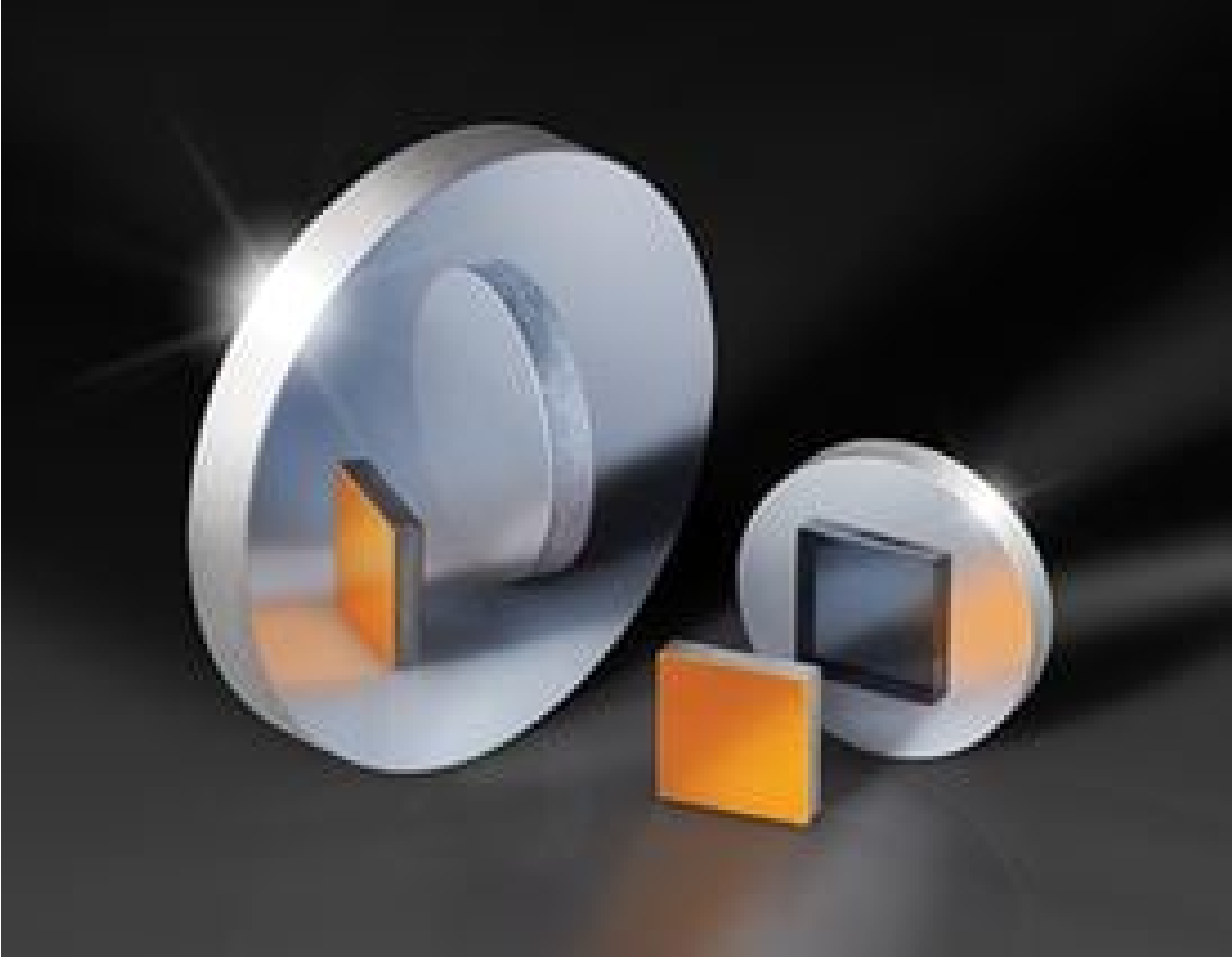

Stock #34-365 3-4 DAYS

⊖ 1 ⊕ **£190.40**

ADD TO CART

Qty 1-5
£190.40

Qty 6+
£151.72

Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Surface Flatness (P-V):
λ/20 (flatness pre-coating)

Substrate: □
[Fused Silica](#) (Corning 7980)

Back Surface:
Commercial Polish

Surface Quality: 20-10
Dimensions (mm): 40.0 x 40.0 +0.00/-0.20
Coating Specification: R _{avg} >95% @ 450 - 650nm
Coating: Enhanced Aluminum (450-650nm)
Coating Type: Metal
Clear Aperture (%): 90.00
Edges: Ground, protective bevel as needed
Parallelism (arcsec): 30.00
Thickness (mm): 5.00
Type: Flat Mirror
Wavelength Range (nm): 450 - 650
Length (mm): 40.00
Width (mm): 40.00

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant