


TECHSPEC® 40mm Enhanced Aluminum Coated, N-BK7 Right Angle Mirror

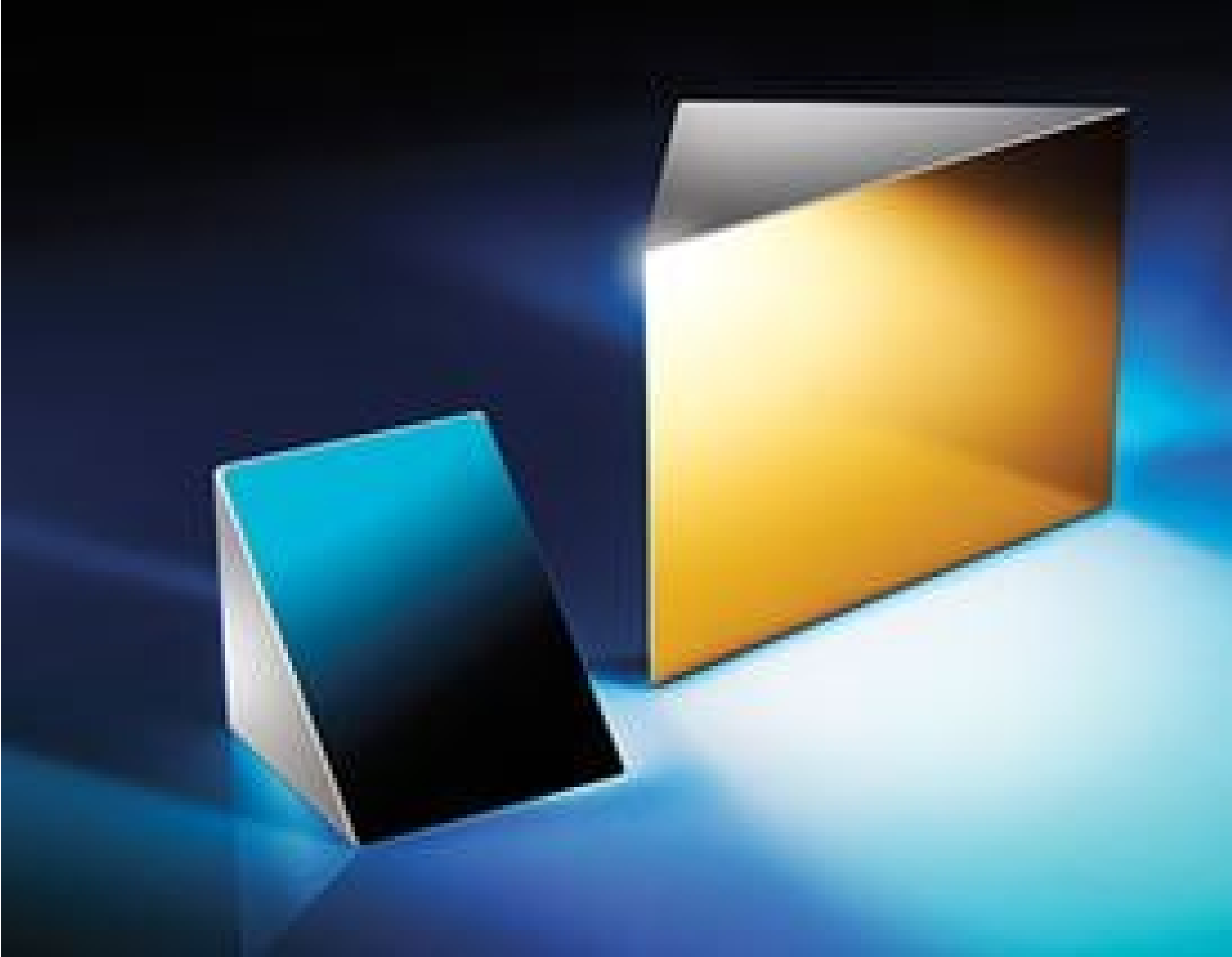

Stock **#45-688** ☐ In Stock

-

1

+

£174.25

ADD TO CART

Qty 1-5
£174.25

Qty 6+
£139.40

Volume Pricing
Request Quote

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Surface Flatness (P-V):
λ/4

Substrate: ☐
[N-BK7](#)

Surface Quality:
60-40

Length of Legs (mm): 40.00
Dimensional Tolerance (mm): ±0.1
Coating Specification: R_{avg} >95% @ 450 - 650nm
Coating: Enhanced Aluminum (450-650nm)
Coating Type: Metal
Angle Tolerance (arcmin): ±2
Bevel: Protective bevel as needed
Clear Aperture CA (mm): 50.91 x 36.00
Length of Hypotenuse (mm): 56.60
Type: Right Angle Mirror
Wavelength Range (µm): 0.45 - 0.65
Wavelength Range (nm): 450 - 650
Damage Threshold, Reference: 0.2 J/cm² @ 532nm, 10ns

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant