


41 x 63.5mm AR Coated Float Glass Window

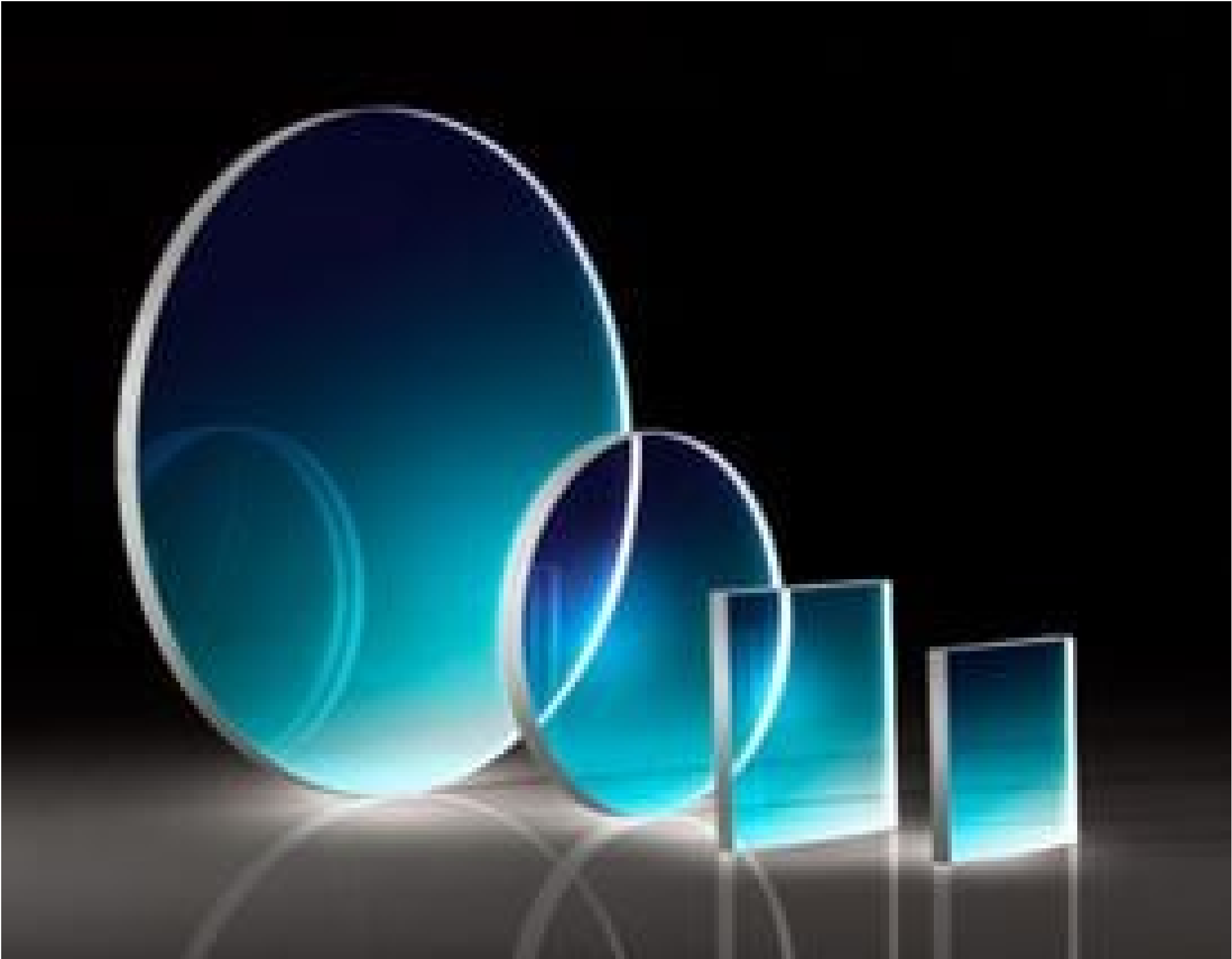

Stock **#32-740** 20+ In Stock

-

1

+

£21^{.80}

ADD TO CART

Volume Pricing	
Qty 1-5	£21.80 each
Qty 6-49	£19.20 each
Qty 50-99	£18.40 each
Need More?	Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

General

Protective Window

Type:

Physical & Mechanical Properties

41.00 x63.50

Dimensions (mm):

3.00 (nominal)

Thickness (mm):

63.50	Length (mm):
41.00	Width (mm):
Fine Ground	Edges:

Optical Properties

BBAR (400-700nm)	Coating:
Float Glass	Substrate: ☐
80-50	Surface Quality:
400 - 700	Wavelength Range (nm):
4 - 6λ	Surface Flatness (P-V):

Regulatory Compliance

Compliant	RoHS 2015:
View	Certificate of Conformance:
Compliant	Reach 247:

Product Details

- Transmits Visible and Near Infrared Wavelengths
- Available Uncoated or with an Anti-Reflection Coating
- Variety of Sizes Available

Float Glass Optical Windows are optical glass with polished faces that are relatively parallel and are typically used as a protective element between two environments. Float glass readily transmits visible and near-infrared wavelengths and can be used in a wide variety of applications. Float Glass Optical Windows are versatile products offered in circular and rectangular options. They are available uncoated or with BBAR (Broadband Anti-Reflective) 400-700nm coating.

Compatible Mounts

