

## 4.5" Angle Mirror Mount



4.5" Angle Mirror Mount

Stock #36-482 **20+ In Stock**

⊖ 1 ⊕ £302<sup>40</sup>

**ADD TO CART**

### Volume Pricing

Qty 1-4	£302.40 each
Qty 5-9	£282.56 each
Qty 10-25	£268.96 each
Need More?	<a href="#">Request Quote</a>

**!** Prices shown are exclusive of VAT/local taxes

### Product Downloads

#### General

Adjustable - Tip-Tilt **Type:**

Square or Rectangular **Type of Optics:**

3 **Number of Adjustment Screws:**

## Physical & Mechanical Properties

Weight (lbs):  
2.0

Construction:  
Black Anodized Aluminum, Stainless Steel

Fine Tilt Angle (°):  
8

Resolution (inches):  
0.015

Fine Tip Angle (°):  
8

Adjustment Screw Pitch (inches):  
0.015

## Threading & Mounting

Size of Compatible Optics (mm):  
12.7 - 114.3

Mounting Plate Size (inches):  
4.5 Sq.

Mounting Plate Screw Holes:  
(49) 1/4-20 on 0.5" Center

## Regulatory Compliance

RoHS 2015:  
[Compliant](#)

Certificate of Conformance:  
[View](#)


Reach 240:  
[Compliant](#)

## Product Details

- 3.0", 4.5", or 6.0" Square Mounting Surface
- Fine Adjustment Screws (64-Pitch) Allow for Tilting
- Mounting Plate with 1/4-20 Threaded Holes

Medium and Large Angle Mirror Mounts are available with a range of mounting plate sizes for mounting optical mirrors. These optical mirror mounts feature 64-pitch fine adjustment screws, allowing for precision tilting in two directions. Both square and rectangular optics can be mounted into these black anodized aluminum and stainless-steel mounts. Medium and Large Angle Mirror Mounts have two 1/4-20 through holes on their angle bases for easy mounting to optical tables or breadboards. These mounts are available in 3", 4.5", and 6" sizes.

## Technical Information

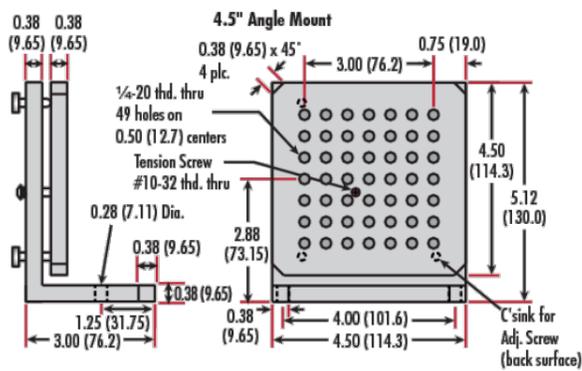

#36-482