
 


TECHSPEC[®] 4mm 3X, 100mm Length, Low NA Tapered Light Pipe

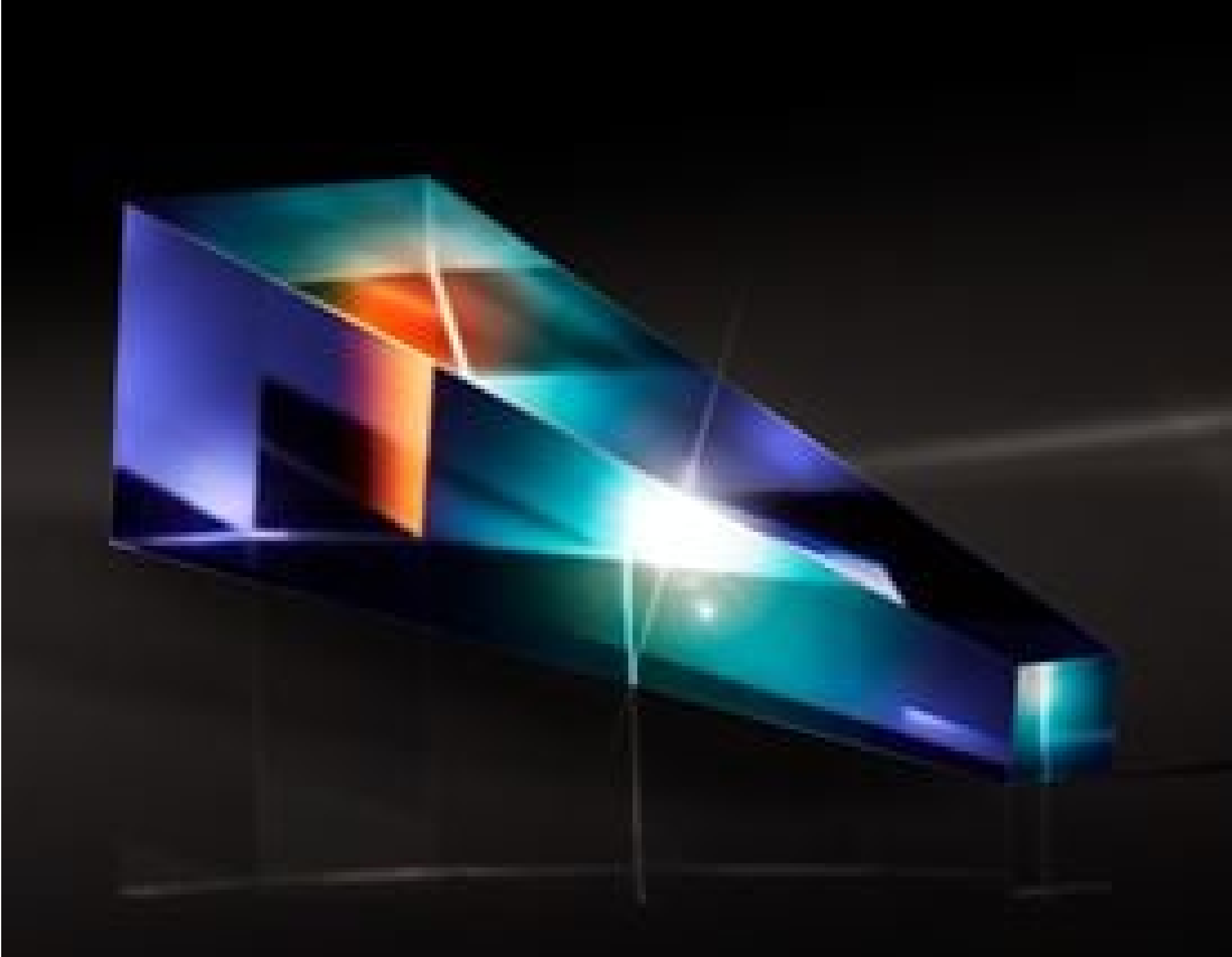

TECHSPEC[®] Tapered Light Pipe Homogenizing Rods



Stock **#63-106** 3-4 DAYS

-

1

+

£144.50

ADD TO CART

Qty 1-5

£144.50

Qty 6+

£115.60

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Coating:

Uncoated

Entrance Aperture (mm):

4 x 4
Exit Aperture (mm): 12 x 12
Substrate: ☐ N-BK7
Length (mm): 100.00
Magnification: 3X
Surface Quality: 60-40
Type: Light Pipe
Parallelism (arcmin): 5.00
Length Tolerance (mm): ±0.3
Aperture Tolerance (mm): ±0.10
Image Orientation: Light Homogenization
Light Source NA: Low
Wavelength Range (nm): 350 - 2200
Surface Flatness (P-V): 1λ

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View