


TECHSPEC[®] 4mm Aperture, 25mm L High NA, Hexagonal Light Pipe

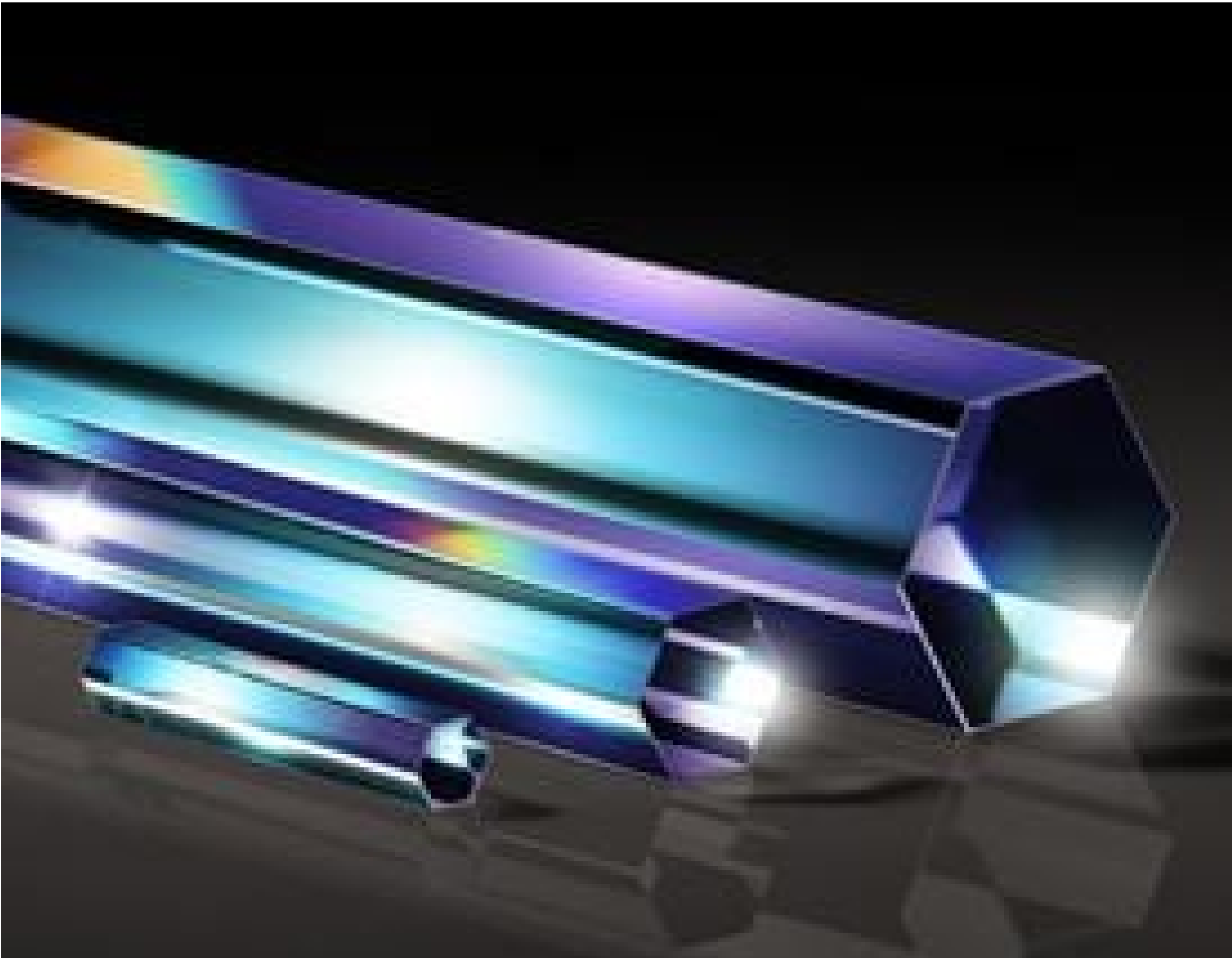

N-BK7 Light Pipe Homogenizing Rods



Stock **#63-082** ☒ In Stock

-

1

+

£85.00

ADD TO CART

Qty 1-5

£85.00

Qty 6+

£68.00

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Coating:

Uncoated

Substrate:

N-BK7
Length (mm): 25.00
Surface Quality: 60-40
Type: Light Pipe
Entrance and Exit Aperture (mm): 4.00
Parallelism (arcmin): 5.00
Length Tolerance (mm): ±0.3
Aperture Tolerance (mm): ±0.10
Image Orientation: Light Homogenization
Light Source NA: High
Wavelength Range (nm): 350 - 2200
Surface Flatness (P-V): 1λ

Regulatory Compliance

RoHS 2015: Compliant
Reach 211: Compliant
Certificate of Conformance: View