


4" x 5", Optical Cast Plastic IR Longpass Filter

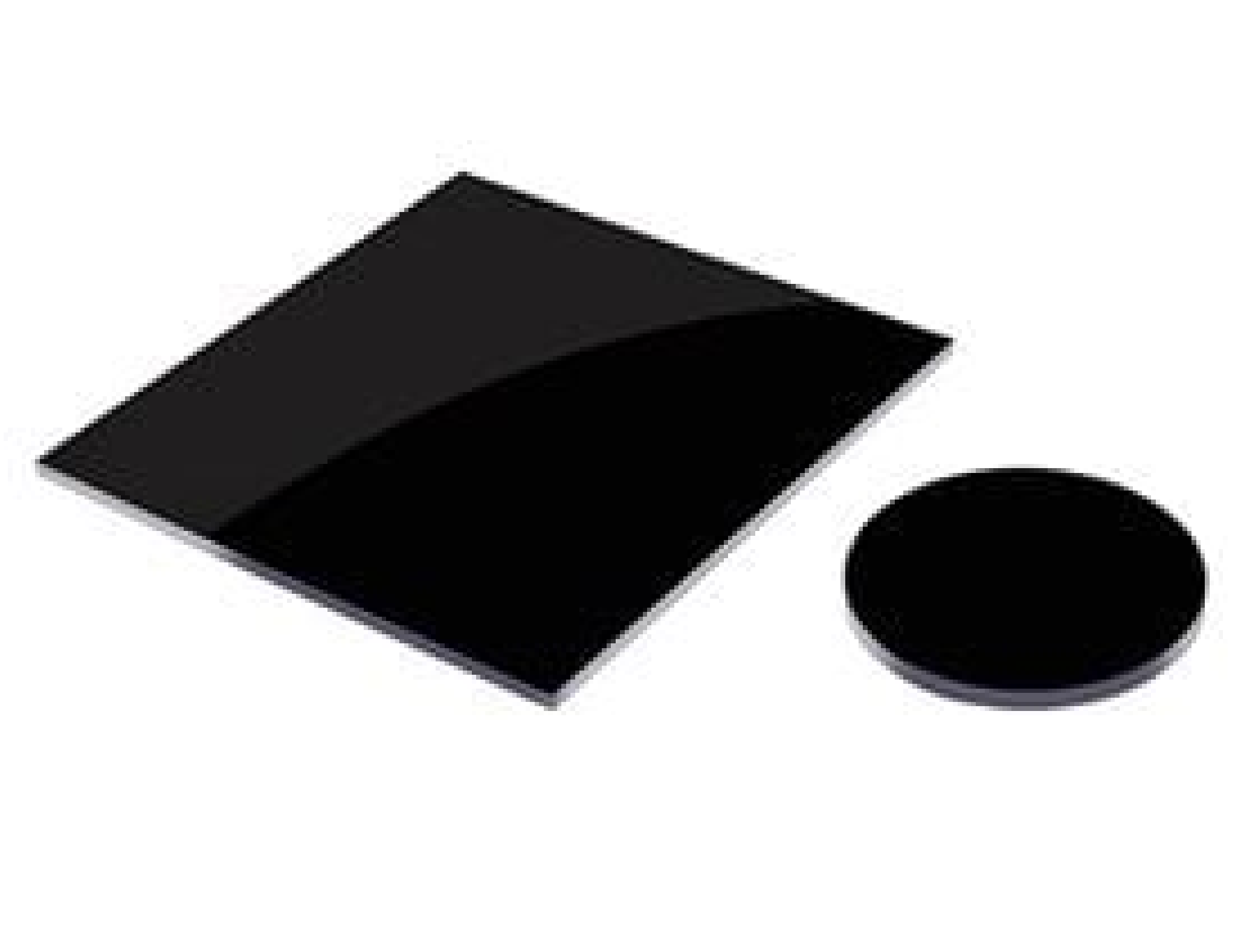

Stock **#43-954** ☐ In Stock

-

1

+

£35.70

ADD TO CART

Qty 1-49

£35.70

Qty 50+

£32.30

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Dimensions (mm):

101.6 x 127.0

Density (g/cm³):

1.320 at 20°C

Substrate: ☐

Thermoset ADC (CR-39®)

Length (mm):

127.00
Operating Temperature (°C): 100 Continuous, 130 One Hour Max
Coating: Uncoated
Color: Black
Index of Refraction n_d: 1.501 @ 20°C
Dimensions (inches): 4 x 5
Thickness (mm): 1.50 Nominal
Transmission (%): >90 (typical)
Type: Longpass Filter
Width (mm): 101.60
Dimensional Tolerance (mm): ±0.3
Abbe Number (v_d): 57.00

Regulatory Compliance

RoHS 2015: Compliant
Reach 223: Compliant
Certificate of Conformance: View