 



50 x 50mm, 0.500mm Spacing, White Ivory Distortion Target

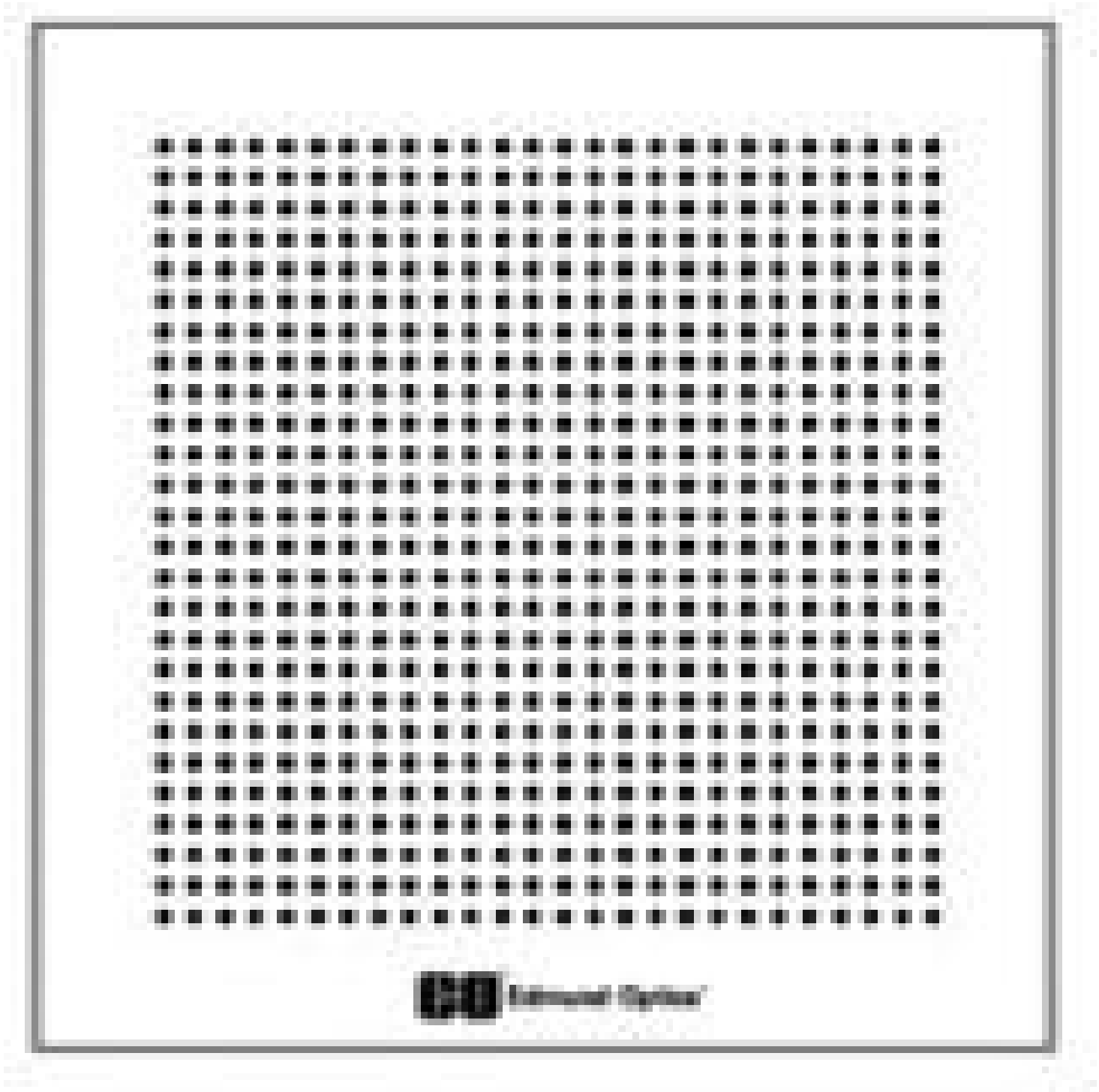

Stock #63-986 3-4 DAYS

-

1

+

£744.60

ADD TO CART

Qty 1-4

£744.60

Qty 5+

£708.22

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Coating:  
Reflective First Surface Chromium  
R<sub>abs</sub> = 50% ±5% @ 550nm

Dot Diameter (mm):  
0.250

|                                                                              |
|------------------------------------------------------------------------------|
| <b>Dot Spacing (mm):</b><br>0.500                                            |
| <b>Substrate:</b><br>White Ivory Soda Lime Glass                             |
| <b>Optical Density OD (Average):</b><br>>3.0                                 |
| <b>Overall Accuracy (mm):</b><br>±0.002                                      |
| <b>Pattern Size (mm):</b><br>50 x 50                                         |
| <b>Dimensions (inches):</b><br>3 x 3                                         |
| <b>Surface Quality:</b><br>40-20                                             |
| <b>Thickness (mm):</b><br>3.20                                               |
| <b>Type:</b><br>Chrome on White Ivory Glass                                  |
| <b>Dot Diameter Tolerance (mm):</b><br>± 0.002                               |
| <b>Dot Spacing Tolerance (mm):</b><br>± 0.002 Center to Center               |
| <b>NIST Certification:</b><br>Serialized NIST Traceable Certificate Included |
| <b>Flatness (inches):</b><br>0.001                                           |

Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Compliant</a>             |
| <b>Reach 209:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |

---