

[See all 21 Products in Family](#)

TECHSPEC®

503nm, 25mm Diameter, Dichroic Laser Beam Combiner



TECHSPEC® Dichroic Laser Beam Combiners

Stock **#86-392** **4 In Stock**

-

1

+

£237⁰⁰

ADD TO CART

Volume Pricing	
Qty 1-5	£237.60 each
Qty 6-25	£201.60 each
Qty 26-49	£187.20 each
Need More?	Request Quote

i Prices shown are exclusive of VAT/local taxes

Product Downloads

General

Dichroic Filter

Type:

Physical & Mechanical Properties

25.00 +0.0/-0.1

Diameter (mm):



Clear Aperture CA (mm):

filters are ideal for multi-laser fluorescence imaging and measurement applications, including laser microscopy and flow cytometry.

Note: These filters are optimized for high spectral performance rather than high Laser Induced Damage Thresholds (LIDT). A typical LIDT for these filters is 1 J/cm² @ 532nm, 10ns. Please [contact us](#) if you require a filter with a higher LIDT value.



Technical Information

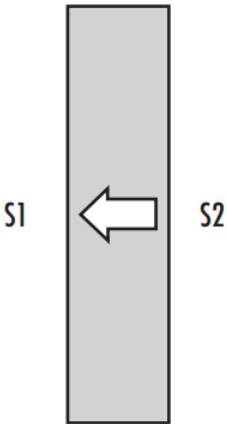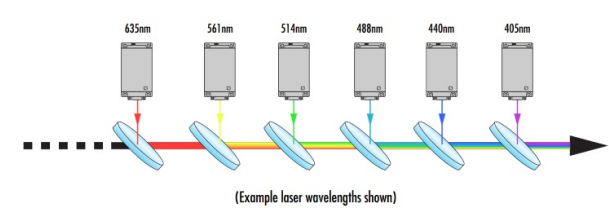

All mounted TECHSPEC® Optical Filters have an arrow on the side of the mount that points to the filter-coated surface for quick reference. Filter oriented such that arrow points to filter coated surface S1. Anti-reflective (AR) coating is applied to S2.

Compatible Mounts