


50.8mm Diameter, Optical Cast Plastic Window

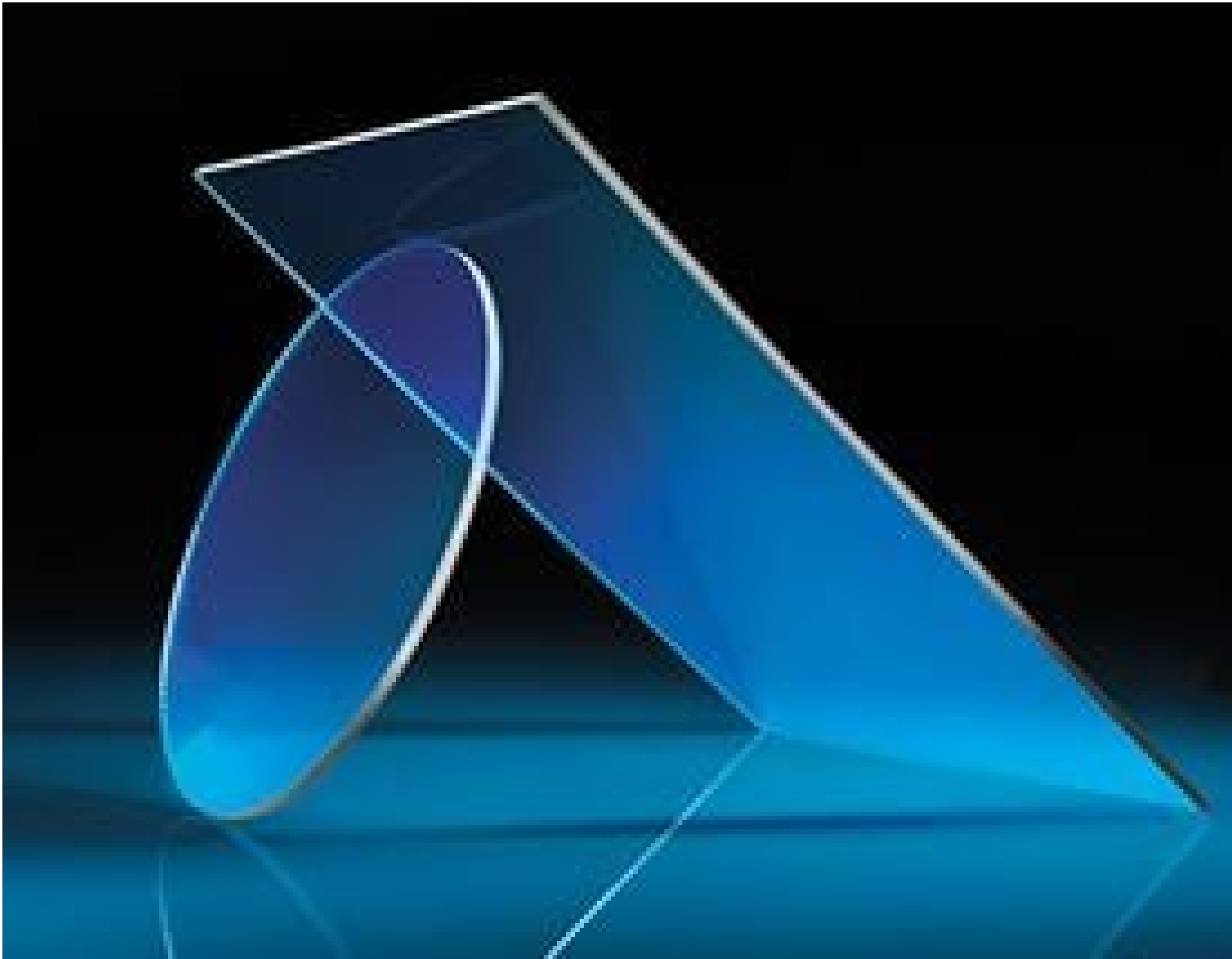

Stock #19-829 3-4 DAYS

- 1 + **£22.95**

ADD TO CART

Qty 1-49
£22.95

Qty 50+
£18.27

Volume Pricing
Request Quote

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Abbe Number (v_d):
57.00

Diameter (mm):
50.80 ±0.3

Diameter (inches):
2.00

Thickness (mm): 1.50 ±0.15
Coating: Uncoated
Density (g/cm³): 1.320
Index of Refraction n_d: 1.501
Operating Temperature (°C): 100 Continuous, 130 for 1 hour
Substrate: Thermoset ADC (CR-39®)
Transmission (%): >90 (typical)
Type: Protective Window
Wavelength Range (nm): 400 - 1500

Regulatory Compliance

RoHS 2015: Compliant
Reach 223: Compliant
Certificate of Conformance: View