


50mm, Red 625nm, MicroBrite Brightfield Ring Light

See More by [Advanced Illumination](#)

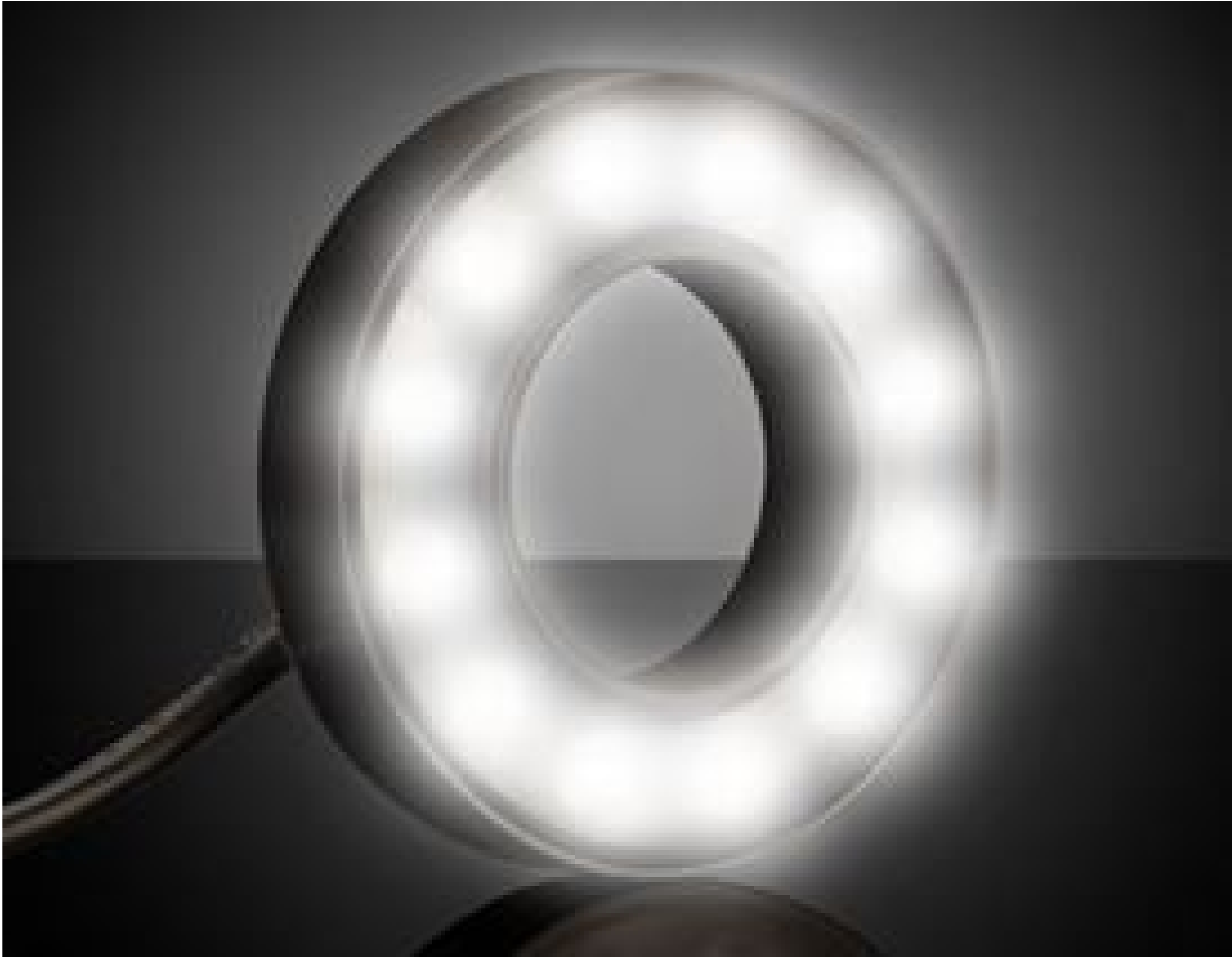

Stock **#18-568** 3-4 DAYS

⊖ 1 ⊕ **£692.75**

ADD TO CART

Qty 1+

£692.75

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Color:
Red

Height (mm):
19.09

Inner Diameter (mm):
50

Input Voltage (V):
24V

Model Number:

RL208M050625IC
Operating Temperature (°C): 0 - 60
Outer Diameter (mm): 95.34
Dimensions (mm): 50.00 x 95.34 x 19.09
Mounting Threads: M4 x 4
Wavelength (nm): 625.00
Weight (g): 299
LED Lifetime (hours): 50,000
Power Supply: Power Supply Required and Sold Separately. USA: #66-855 Europe: #66-855 Japan: #66-855 Korea: Not Available China: #66-855
Type of Illumination: LED Illuminator
Note: Optional Manual Intensity Adjustment #86-887 and #89-555 are Available
Manufacturer: Advanced Illumination
Geometry: Ring Light
Maximum Input Current: 0.12A
Illumination Mode: Constant
Environmental Rating: IP50

Regulatory Compliance

RoHS 2015: Exempt
Certificate of Conformance: View
Reach 233: Contains SVHC(s)