

5" square English/Metric Adapter



Stock **#55-384** 20+ In Stock

-

1

+

£47^{.71}

ADD TO CART

Volume Pricing	
Qty 1+	£47.71 each
Need More?	Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

SPECIFICATIONS

General

Type:

Universal

Note:

See Figure B

Compatible Breadboard:

Metric	
Physical & Mechanical Properties	
0.5	Thickness (inches):
5.0	Length (inches):
5.0	Width (inches):
Anodized Aluminum	Construction:
Threading & Mounting	
Mounting Threads: (14) ¼-20, (2) M6 S.H.C.S Slots, (1) ¼ and M6 S.H.C.S C'bore	
Regulatory Compliance	
Compliant	RoHS 2015:
View	Certificate of Conformance:
Compliant	Reach 250:

PRODUCT DETAILS

- Connects Metric/English Components to English/Metric Breadboards
- Standard ¼-20 or M6 x 1.0 Holes and Slots
- Center C'bore Can Be Used for ¼ or M6 S.H.C.S.
- Large and Small Sizes
- Black Anodized Aluminum Construction

Metric-English adapter plates are designed to connect our new Metric components to English breadboards while English-Metric adapter plates connect English components to Metric breadboards. These adapter plates are universal and can also be used to connect rotary stages, translation stages, and lab jacks together. See drawings for more details. For versatility, center counterbore is designed to accept both ¼ and M6 socket head cap screws. Both are available in large 5" square or 2.5" square sizes.

TECHNICAL INFORMATION

Type	A	B	C	D	E Mounting Thread	F Slots for S.H.C.S	Stock No.
Figure A	50.0mm	25.4mm	50.8mm	25.0mm	M6 x 1.0	¼	#55-383
Figure A	2"	0.984"	1.969"	1"	¼	M6	#55-385
Figure B	101.6mm	25.8mm	101.6mm	25.0mm	M6 x 1.0	¼	#55-382
Figure B	4"	0.969"	3.937"	1"	¼-20	M6	#55-384

Breadboard Adapter Plates

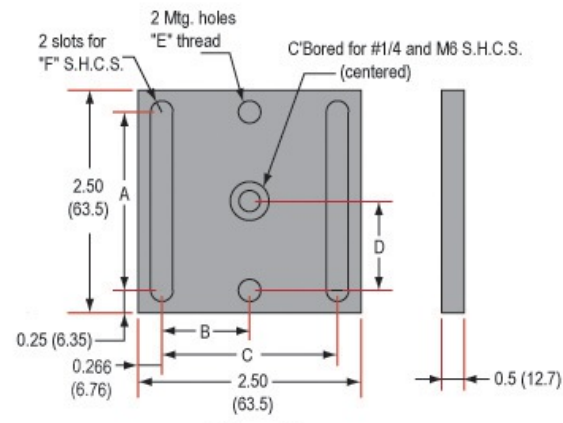


Figure A

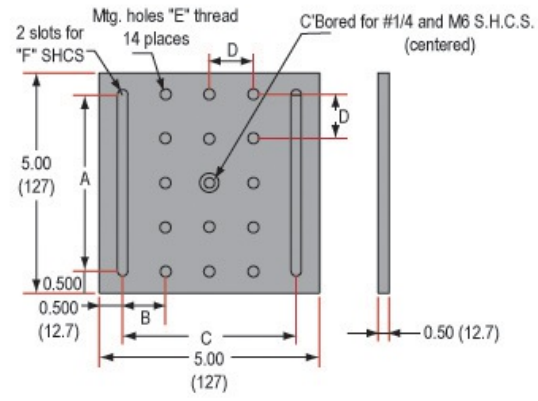


Figure B

Units: inches (mm)