


76.2 x 76.2 x 3mm High Efficiency Window

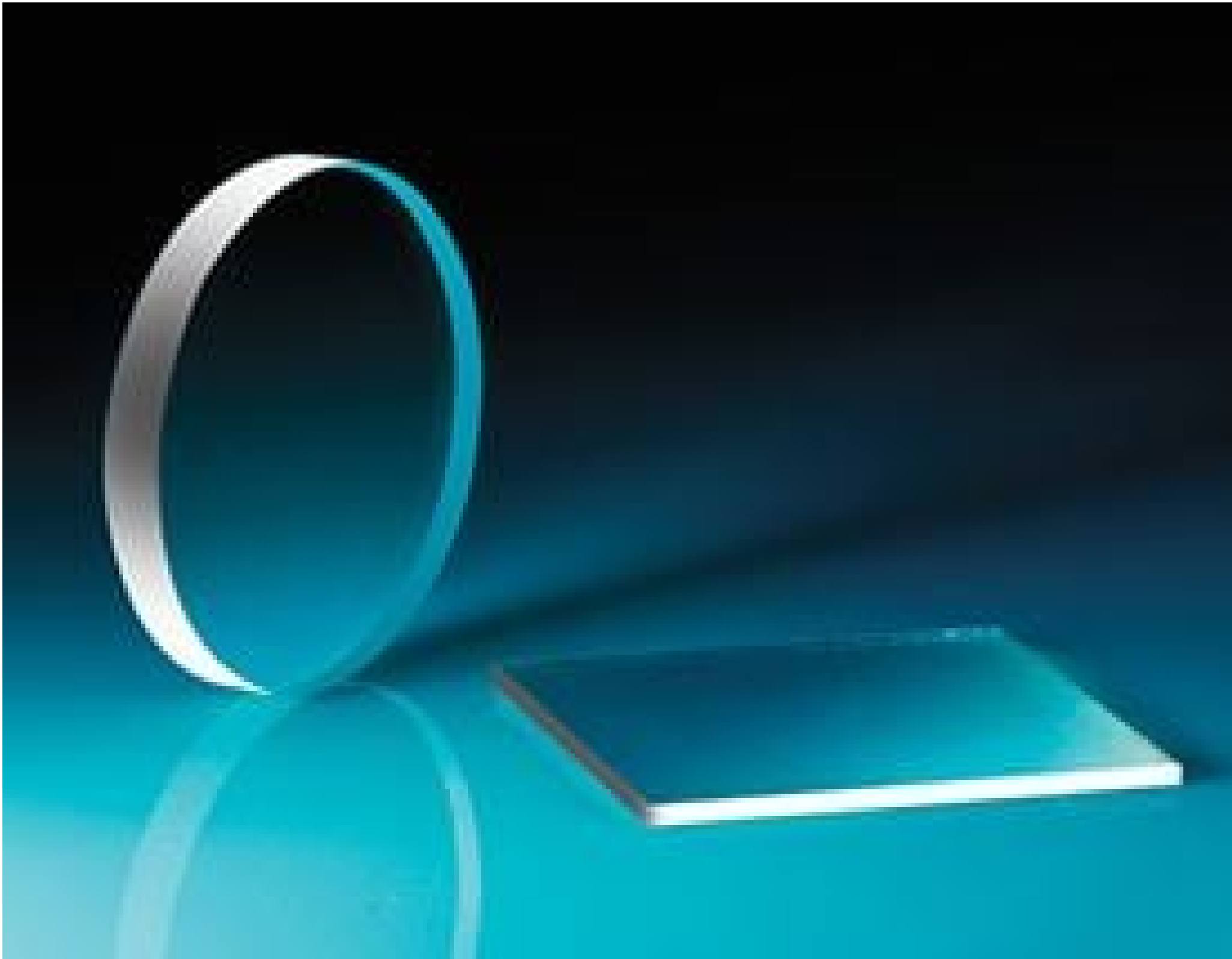

Stock **#46-101** ☐ In Stock

-

1

+

£24.65

ADD TO CART

Qty 1-5
£24.65
Qty 6+
£19.76
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Angle of Incidence (°):
0

Bevel:
Protective as needed

Clear Aperture (%):
≥90

Clear Aperture CA (mm): 68.58 x 68.58
Dimensions (mm): 76.20 x 76.20
Thickness (mm): 3.00 ±0.25
Coating: BBAR (425-700nm)
Coating Specification: R _{avg} ≤0.5% @ 425 - 700nm
Edges: Seamed
Substrate: Float Glass
Surface Quality: 80-50
Transmission (%): 95.6 Average (typical)
Type: Protective Window
Wavelength Range (nm): 425 - 700
Length (mm): 76.20
Width (mm): 76.20

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant