


92 Grooves/mm, 12.7mm Sq, Transmission Grating Beamsplitter

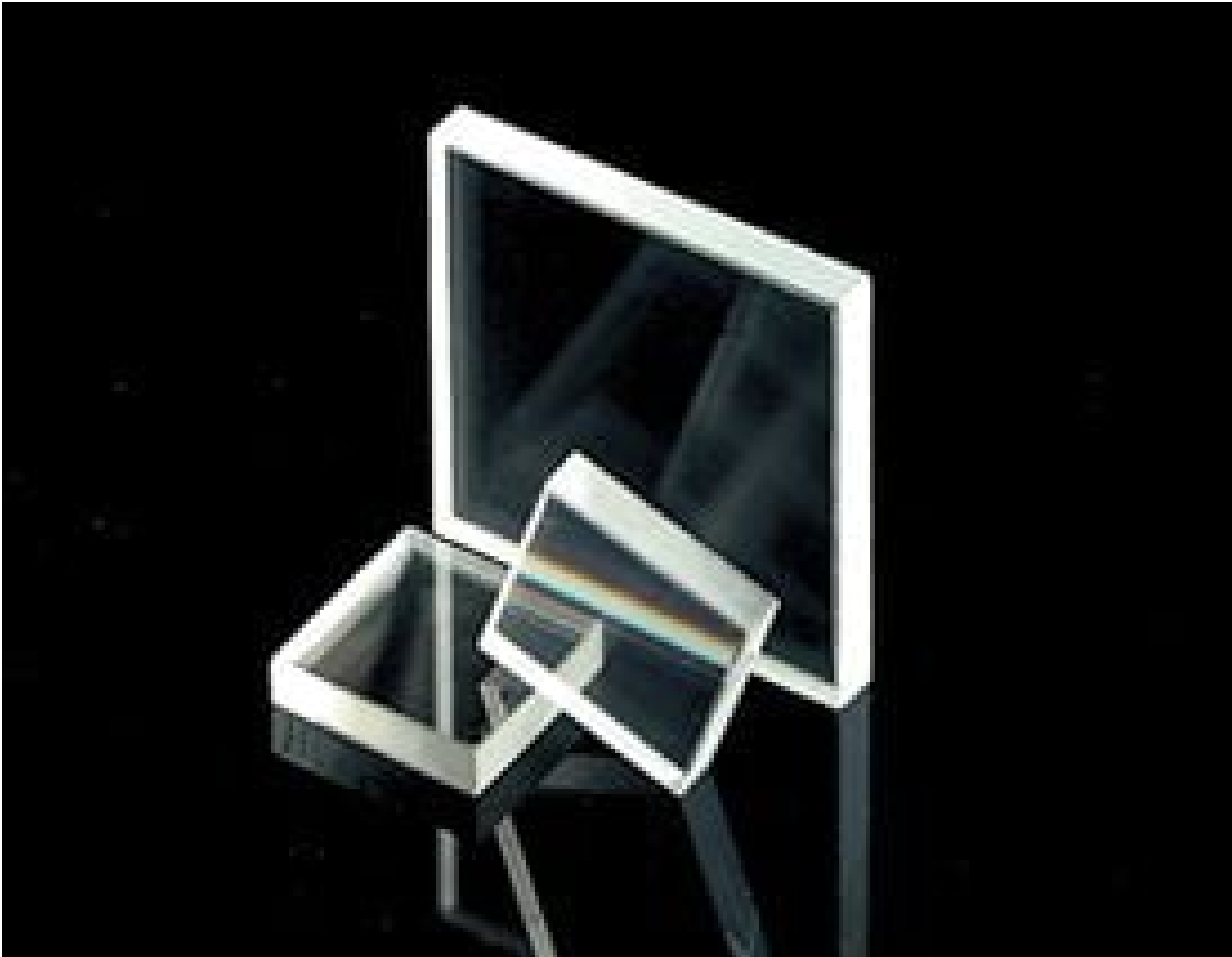

Stock #46-071 3-4 DAYS

-

1

+

£110.50

ADD TO CART

Qty 1-10
£110.50
Qty 11+
£99.45
Volume Pricing
Request Quote

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Groove Density (grooves/mm):
92

Design Wavelength DWL (nm):
632.8

Dimensions (mm):
12.7 x 12.7 ±0.5

Construction: Blazed Grating
Length (mm): 12.70
Substrate: ☐ E270
Thickness (mm): 3.00 ±0.5
Type: Transmission Diffraction Grating
Width (mm): 12.70

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View