


TECHSPEC[®] 9mm Dia. x 12mm FL Uncoated, UV Plano-Convex Lens

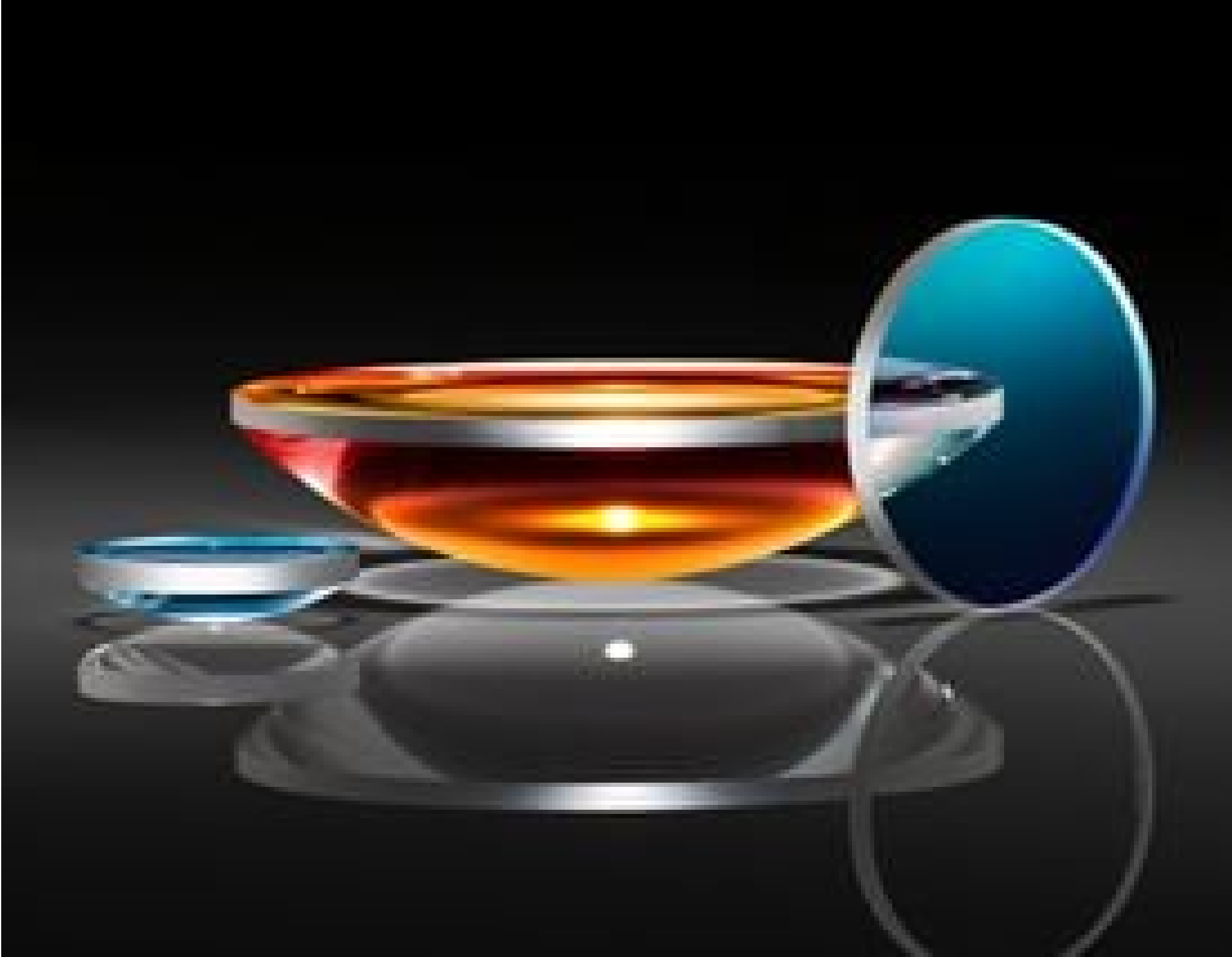

UV Fused Silica Plano-Convex (PCX) Lenses



Stock **#48-666** ☐ In Stock

☐ [Other Coating Options](#)

-

1

+

£102.00

ADD TO CART

Qty 1-5

£102.00

Qty 6+

£81.60

Volume Pricing

[Request Quote](#)

 Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
9.00 +0.0/-0.025

Effective Focal Length EFL (mm): 12.00 @ 587.6nm
Back Focal Length BFL (mm): 9.26
Coating: Uncoated
Substrate:  Fused Silica (Corning 7980)
Surface Quality: 40-20
Power (P-V) @ 632.8nm: 1.5λ
Irregularity (P-V) @ 632.8nm: λ/4
Focal Length Tolerance (%): ±1
Centering (arcmin): <1
Center Thickness CT (mm): 4.00 ±0.05
Edge Thickness ET (mm): 1.66
Radius R₁ (mm): 5.50
Clear Aperture CA (mm): 8.1
f/#: 1.33
Numerical Aperture NA: 0.38
Type: Plano-Convex Lens
Bevel: Protective bevel as needed
Wavelength Range (nm): 200 - 2200

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View