


Coarse/Fine Movement, 1/4-20, Rack & Pinion

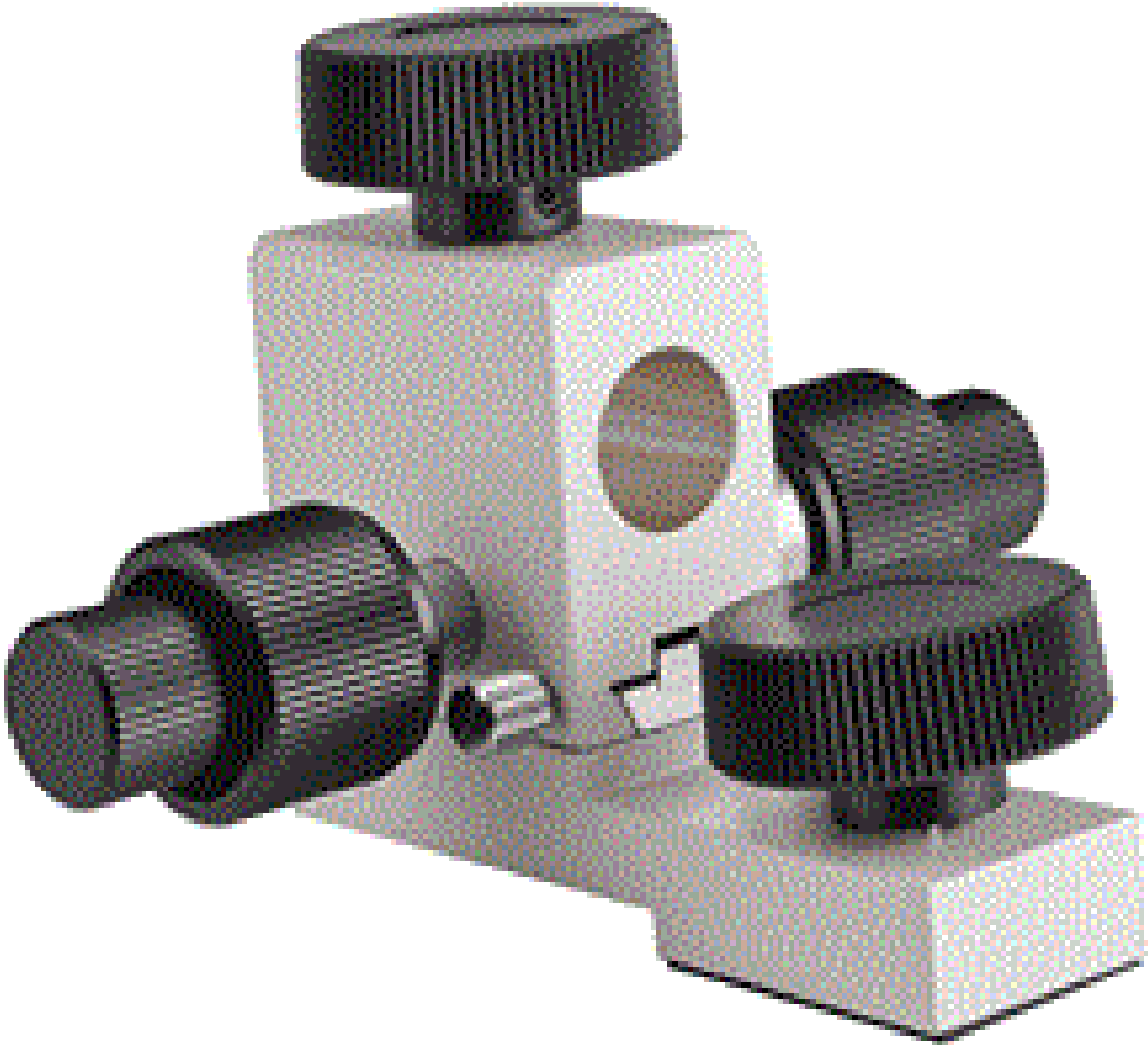

#54-794

Stock **#54-794** 6 In Stock

-

1

+

£464⁰⁰

ADD TO CART

Volume Pricing	
Qty 1+	£464.00 each
Need More?	Request Quote

Prices shown are exclusive of VAT/local taxes

Product Downloads

SPECIFICATIONS

General

Rack and Pinion Mount	Type:
1/4-20 Stud	Note:

Coarse/Fine Movement	Type of Adjustment:
Physical & Mechanical Properties	
Dimensions (mm): Rack and Pinion Block: 50 H x30 W x50 L	
Travel (mm): 35 (+23/-12) in Y	
Travel Per Knob Rotation (mm): 25.5 coarse, 3.2 fine	
Load Capacity (kg): 2.00	
Type of Movement: Linear (Y)	
Optical Centerline from Post (mm): 51.00	
Threading & Mounting	
Mounting Post Hole and Thread: 3/4" Diameter Post 1/4-20 Tapped Hole	
Regulatory Compliance	
Exempt	RoHS 2015:
Contains SVHC(s)	Reach 224:
View	Certificate of Conformance:

PRODUCT DETAILS

- Coarse or Fine Motion Available
 - Thru Holes for Integrating Lenses
 - 1/4-20 Stud for Mounting Cameras
 - [Imaging System Bases](#), [Stainless Steel Posts](#), and [Accessories](#) also Available
- Rack and Pinion Focusing Mounts for Imaging Systems add additional focus ability to imaging systems. Thru Holes are ideal for use with [TECHSPEC® VZM™ Zoom Imaging Lenses](#) or other imaging lenses. Rack and Pinion Movement with 1/4-20 stud can be used with any compatible camera or imaging lens. Rack and Pinion Focusing Mounts for Imaging Systems are offered with either coarse or fine motion.[Imaging System Bases](#), [Stainless Steel Posts](#), and [Accessories](#) are also available.