

Adapter Plate for #55-028



#55-037

#55-037

Stock **#55-037** **20+ In Stock**

⊖ 1 ⊕ £30²⁰

ADD TO CART

Volume Pricing

Qty 1-9	£30.20 each
Qty 10+	£27.12 each
Need More?	Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

General

Adapter Brackets & Plates

Type:

Physical & Mechanical Properties

Length (inches):
1.57

Length (mm):
40.00

40 x 40 x 5

Dimensions (mm):

Threading & Mounting

Mounting Threads:

(4) M2 x 0.4, (4) M3 x 0.5, (1) 1/4-20

Regulatory Compliance

RoHS 2015:

Compliant

Certificate of Conformance:

[View](#)

Reach 247:


Compliant

Product Details

- Precision Micrometer Drive and Manual Drive Options
- 360° Coarse Rotation
- Micrometer Drive Models Provide $\pm 5^\circ$ Fine Rotation
- Black Anodized Aluminum Construction

Metric Rotary Stages feature slide-fit guide system, enabling 360° course rotation. Micrometer drive models feature a precision metric micrometer and a switchable clamp mechanism to change between course and fine movements for precise $\pm 5^\circ$ angular adjustment at any position. The manual drive model provides a smooth manual adjustment with 360° coarse movement, 1° increments. Metric Rotary Stages feature a locking mechanism to fix the stage position. For breadboard mounting, use the [Metric Base Plates](#).

Technical Information

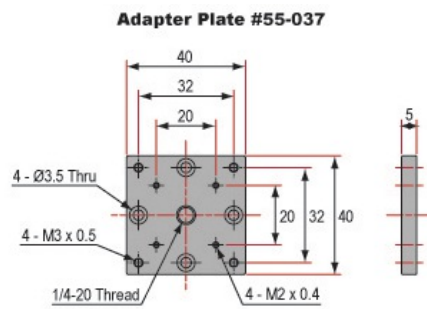

Units: mm