

Adapter Plate for #55-028



#55-037

#55-037

Stock **#55-037** 20+ In Stock

-

1

+

£30²⁰

ADD TO CART

Volume Pricing	
Qty 1-9	£30.20 each
Qty 10+	£27.12 each
Need More?	Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

General

Adapter Brackets & Plates

Type:

Physical & Mechanical Properties

1.57

Length (inches):

40.00

Length (mm):


40 x40 x5		Dimensions (mm):
Threading & Mounting		
		Mounting Threads:
(4) M2 x0.4, (4) M3 x0.5, (1) 1⁄4-20		
Regulatory Compliance		
		RoHS 2015:
Compliant		
		Certificate of Conformance:
View		
		Reach 247:
Compliant		

Product Details

- Precision Micrometer Drive and Manual Drive Options
- 360° Coarse Rotation
- Micrometer Drive Models Provide ±5° Fine Rotation
- Black Anodized Aluminum Construction

Metric Rotary Stages feature slide-fit guide system, enabling 360° course rotation. Micrometer drive models feature a precision metric micrometer and a switchable clamp mechanism to change between course and fine movements for precise ±5° angular adjustment at any position. The manual drive model provides a smooth manual adjustment with 360° coarse movement, 1° increments. Metric Rotary Stages feature a locking mechanism to fix the stage position. For breadboard mounting, use the [Metric Base Plates](#).

Technical Information

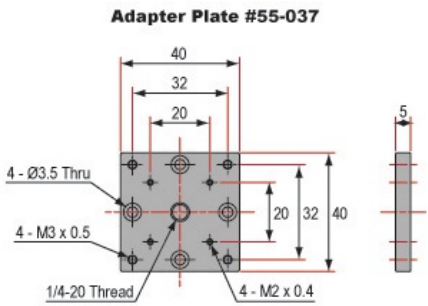

Units: mm