 


Adapter Plate for #55-029



#55-038



Stock **#55-038** **5 In Stock**

⊖ 1 ⊕ £31⁰⁰

ADD TO CART

Volume Pricing

Qty 1-9	£31.00 each
Qty 10+	£27.84 each
Need More?	Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

General

Adapter Brackets & Plates **Type:**

Physical & Mechanical Properties

2.36 **Length (inches):**

60.00 **Length (mm):**

60 x 60 x 7 **Dimensions (mm):**

Threading & Mounting

Mounting Threads:
(4) M4 x 0.7, (4) M3 x 0.5, (4) M2 x 0.4, (1) 1/4-20

Regulatory Compliance

RoHS 2015:
[Compliant](#)

Certificate of Conformance:
[View](#)


Reach 247:
[Compliant](#)

Product Details

- Precision Micrometer Drive and Manual Drive Options
- 360° Coarse Rotation
- Micrometer Drive Models Provide $\pm 5^\circ$ Fine Rotation
- Black Anodized Aluminum Construction

Metric Rotary Stages feature slide-fit guide system, enabling 360° course rotation. Micrometer drive models feature a precision metric micrometer and a switchable clamp mechanism to change between course and fine movements for precise $\pm 5^\circ$ angular adjustment at any position. The manual drive model provides a smooth manual adjustment with 360° coarse movement, 1° increments. Metric Rotary Stages feature a locking mechanism to fix the stage position. For breadboard mounting, use the [Metric Base Plates](#).

Technical Information

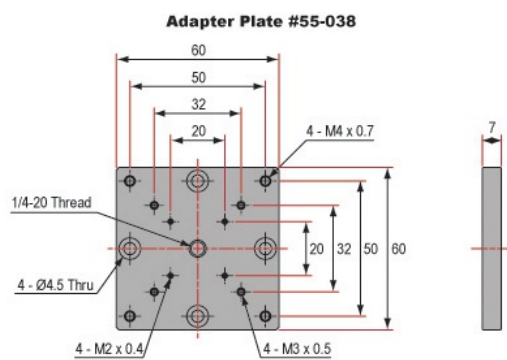

Units: mm