 



Hoya B390 (UV-VIS) 50.8mm Square, Colored Glass Bandpass Filter

See More by [Hoya](#)

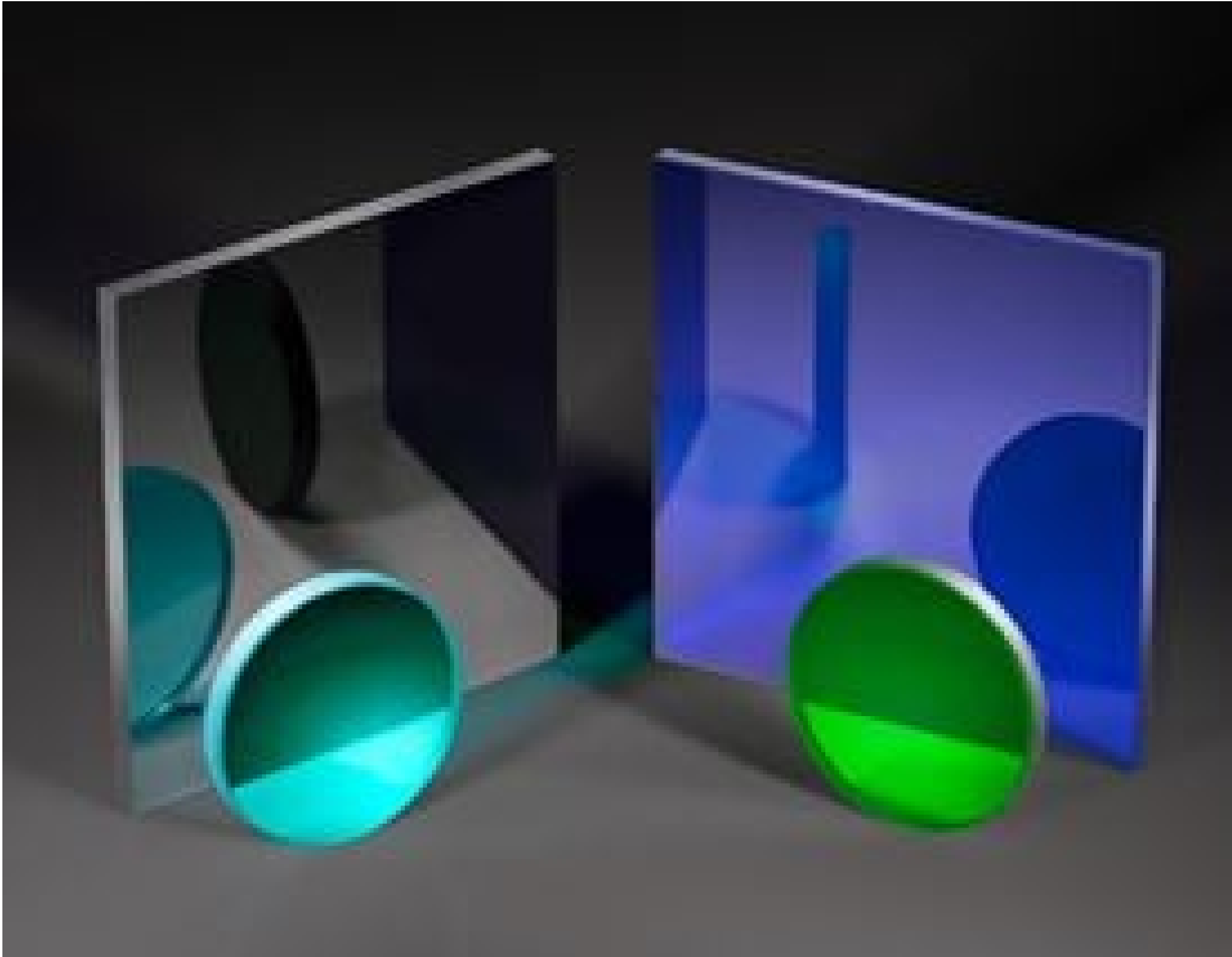

Stock **#48-640** 3-4 DAYS

- 1 + **£91.80**

ADD TO CART

Qty 1-10
£91.80

Qty 11+
£81.60

Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Dimensions (mm):
50.8 x 50.8

Center Wavelength CWL (nm):

390.00
Density (g/cm³): 2.57
Full Width-Half Max FWHM (nm): 125.00
Glass/Filter Number: Hoya B390
Substrate: ☐ Colored Glass
Length (mm): 50.80
Coating: Uncoated
Color: Blue-Violet
Surface Quality: 60-40
Thickness (mm): 2.50
Thickness Tolerance (mm): ±0.2
Type: Bandpass Filter
Wavelength: UV-VIS
Width (mm): 50.80
Parallelism (arcmin): ≤2
Dimensional Tolerance (mm): +0/-0.25

Regulatory Compliance

RoHS 2015: Exempt
Reach 224: Compliant
Certificate of Conformance: View