


## Color Scanner Test Target

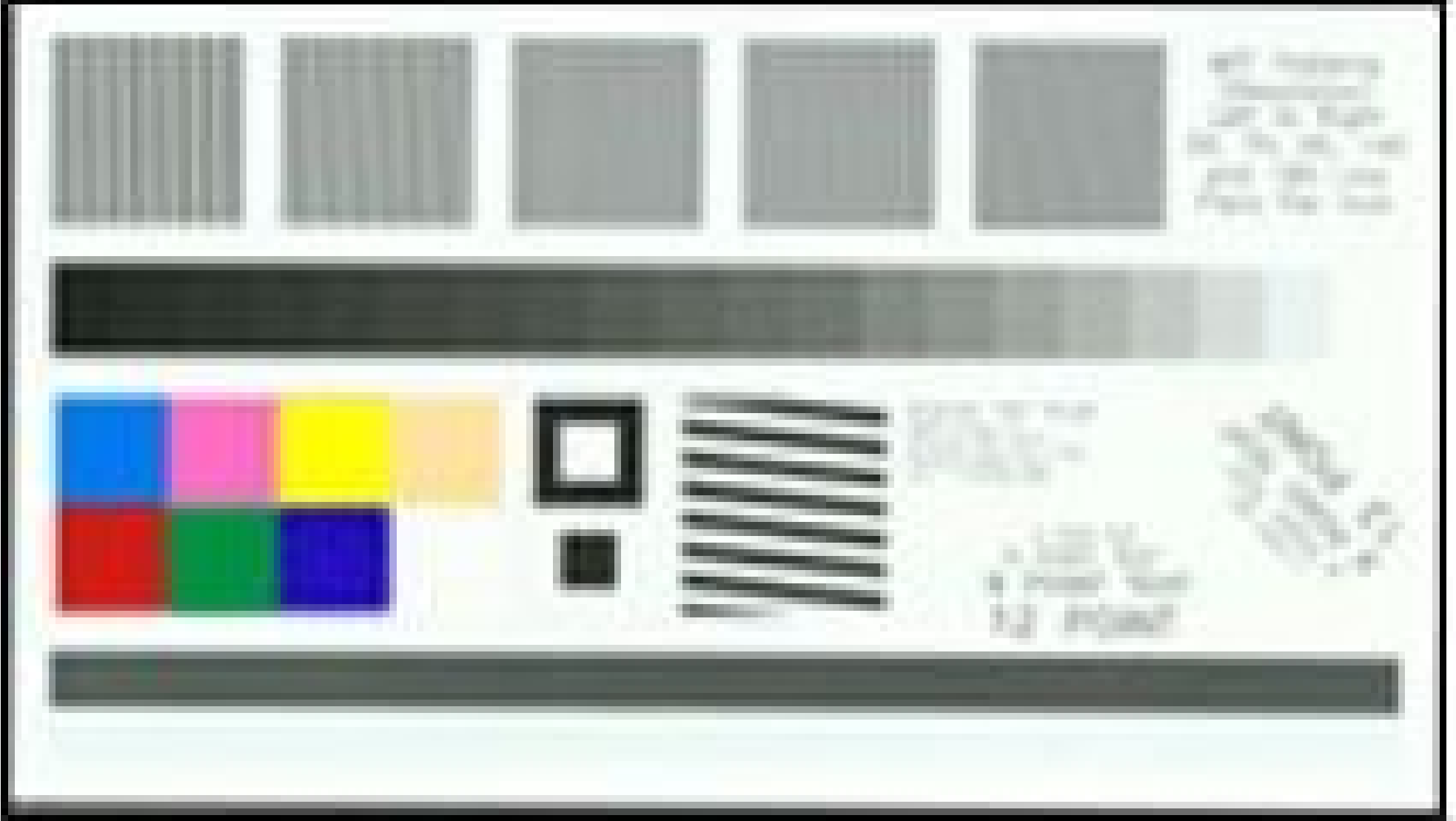

Stock **#58-197** **3 In Stock**

1  £257.<sup>60</sup>

**ADD TO CART**

### Volume Pricing

Qty 1-4	£257.60 each
Qty 5+	£245.04 each
Need More?	<a href="#">Request Quote</a>

**!** Prices shown are exclusive of VAT/local taxes

### Product Downloads

### General

**Note:**

Colors on Target: CYAN Azure Blue #72, MAGENTA True Pink #337, YELLOW Medium Yellow # 10, AMBER Bastard Amber #02, RED Fire #19, GREEN Moss Green #89, BLUE Brilliant Blue #69, WHITE

**NIST Certification:**

No

### Physical & Mechanical Properties

110 x 190 **Pattern Size (mm):**

110 x 190 **Dimensions (mm):**

## Optical Properties

Photo Paper **Substrate:**

## Regulatory Compliance

**RoHS 2015:**  
[Compliant](#)

**Certificate of Conformance:**  
[View](#)

**Reach 235:**  
[Compliant](#)

## Product Details

- Ideal for Evaluation of Color Flatbed Scanners

The Color Scanner Test Target is a critical tool for evaluating the performance of any digital imaging or scanning device. The target features 5 resolution patterns (30, 75, 95, 140, and 180 linepairs per inch), 20 density step wedge, various alphanumeric, 2 constant density strips, 8 color patches, and 10:1 ratio angle ronchi ruling.

## Technical Information

