


Concentric Square Target

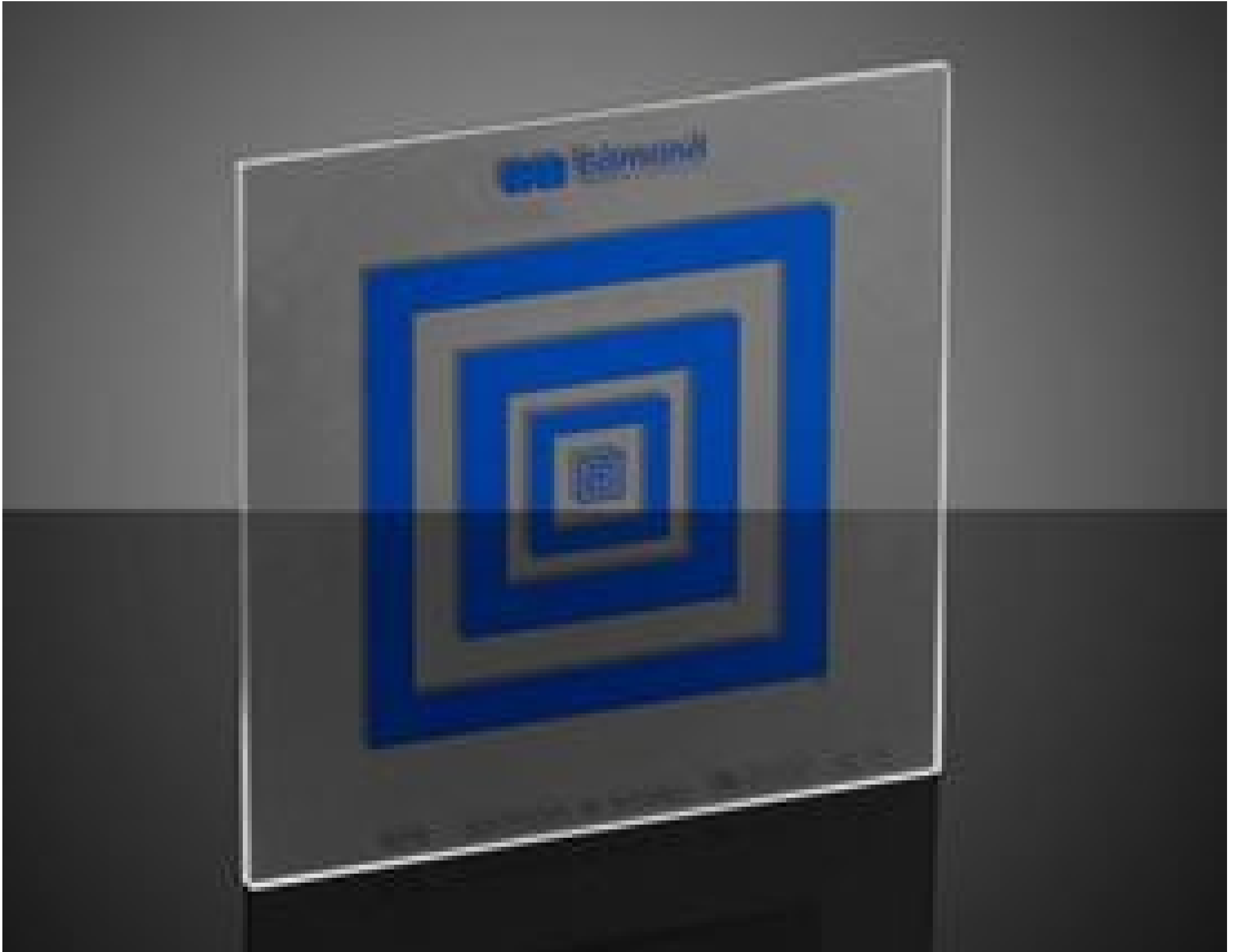

#46-248

Stock **#46-248** **2 In Stock**

⊖ 1 ⊕ £536.⁰⁰

ADD TO CART

Volume Pricing	
Qty 1-4	£536.00 each
Qty 5+	£509.92 each
Need More?	Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

Physical & Mechanical Properties

Pattern Size (mm):
1, 2, 3, 4, 5, 10, 15, 20, 30, 40, 50

Dimensions (mm):
76.2 x 76.2

Thickness (mm):
1.50

Line Width Tolerance (mm):
±0.001

Optical Properties

Coating:

Vacuum Deposited Chromium Oxide (specular reflectivity <5% @550nm)

Substrate:

Float Glass

Surface Quality:

20-10

Surface Flatness (P-V):

λ /mm

Regulatory Compliance

RoHS 2015:

[Compliant](#)

Certificate of Conformance:

[View](#)

Reach 240:

[Compliant](#)

Product Details

- For Calibration of Measurement Software
- NIST Traceable Certificate of Accuracy Included
- 1mm to 50mm Squares

Concentric Square Targets provide an accurate means of calibrating measurement software for image processing. The squares vary in dimensions to accommodate different fields of view. The square targets are NIST Traceable Certificate of Accuracy included. Concentric Square Targets are offered in 1 to 50mm pattern sizes. Included in the packaging is a serialized NIST Traceable Certificate of Accuracy per ML-STD-45662A