 



# Hoya B390 (UV-VIS) 12mm Dia., 1mm Thick, Colored Glass Bandpass Filter

See More by [Hoya](#)

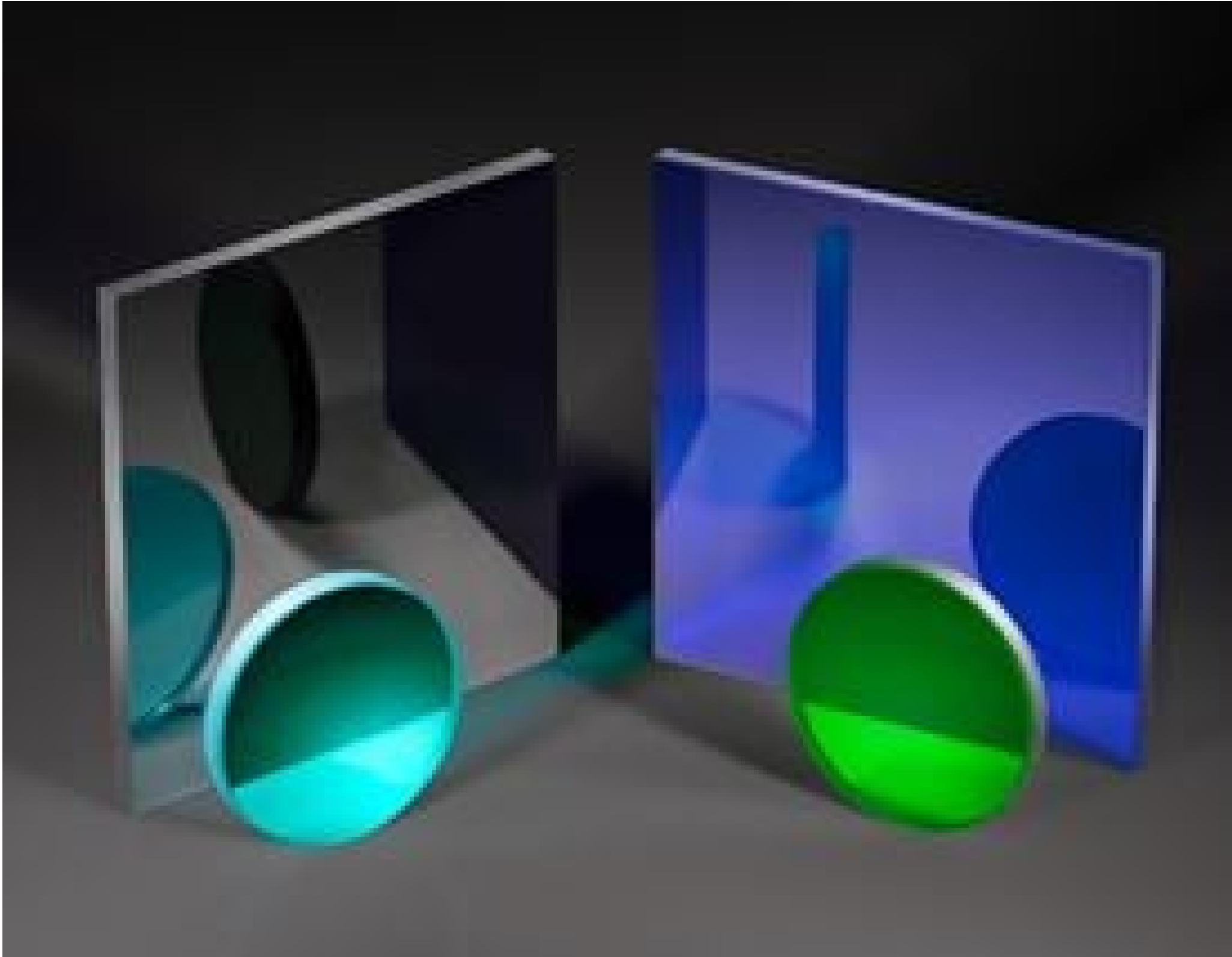

Stock **#18-781** 3-4 DAYS

[Additional Bandwidths](#)

⊖ 1 ⊕

**£31.45**

ADD TO CART

Qty 1-10

£31.45

Qty 11+

£28.05

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):  
12.00

|                                                                  |
|------------------------------------------------------------------|
| <div>Center Wavelength CWL (nm):<br/>390.00</div>                |
| <div>Density (g/cm³):<br/>2.57</div>                             |
| <div>Full Width-Half Max FWHM (nm):<br/>125.00</div>             |
| <div>Glass/Filter Number:<br/><a href="#">Hoya B390</a></div>    |
| <div>Substrate: <input type="checkbox"/><br/>Colored Glass</div> |
| <div>Coating:<br/>Uncoated</div>                                 |
| <div>Color:<br/>Blue-Violet</div>                                |
| <div>Surface Quality:<br/>60-40</div>                            |
| <div>Thickness (mm):<br/>1.00</div>                              |
| <div>Thickness Tolerance (mm):<br/>±0.1</div>                    |
| <div>Type:<br/>Bandpass Filter</div>                             |
| <div>Wavelength:<br/>UV-VIS</div>                                |
| <div>Parallelism (arcmin):<br/>≤1</div>                          |
| <div>Dimensional Tolerance (mm):<br/>±0.2</div>                  |

### Regulatory Compliance

|                                                                 |
|-----------------------------------------------------------------|
| <div>RoHS:<br/><a href="#">Compliant</a></div>                  |
| <div>Certificate of Conformance:<br/><a href="#">View</a></div> |