 



Hoya B390 (UV-VIS) 25.4mm Dia., 1mm Thick, Colored Glass Bandpass Filter

See More by [Hoya](#)

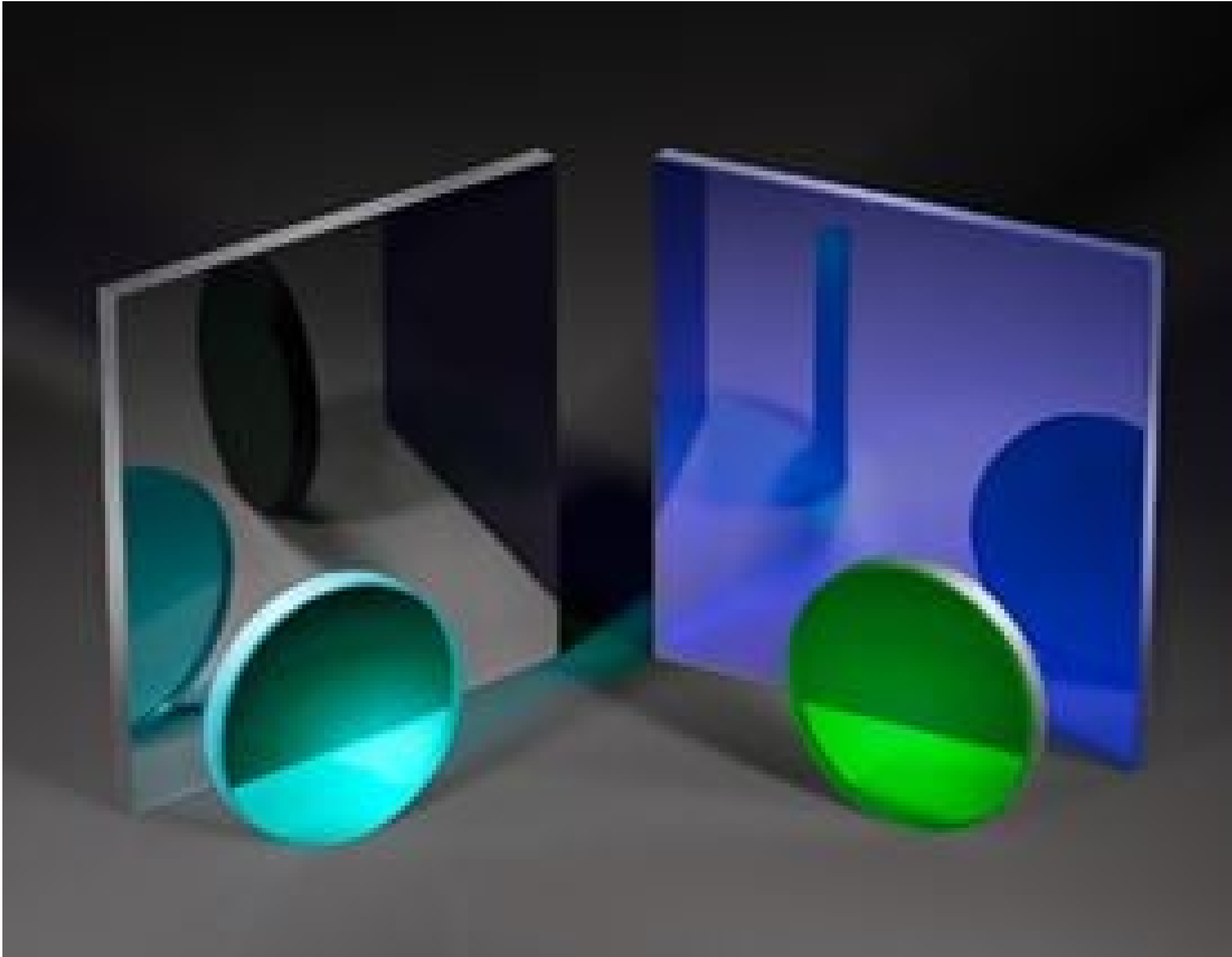

Stock **#18-782** 3-4 DAYS

[Additional Bandwidths](#)

-

1

+

£53.55

ADD TO CART

Qty 1-10

£53.55

Qty 11+

£47.60

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
25.40

Center Wavelength CWL (nm): 390.00
Density (g/cm³): 2.57
Full Width-Half Max FWHM (nm): 125.00
Glass/Filter Number: Hoya B390
Substrate: ☐ Colored Glass
Coating: Uncoated
Color: Blue-Violet
Surface Quality: 60-40
Thickness (mm): 1.00
Thickness Tolerance (mm): ±0.1
Type: Bandpass Filter
Wavelength: UV-VIS
Parallelism (arcmin): ≤2
Dimensional Tolerance (mm): ±0.2

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View