

TECHSPEC[®] Mounting Clamp, 160mm Inner Diameter



Mounting Clamp, 160mm Inner Diameter

Stock **#56-873** **20+ In Stock**

-

1

+

£370⁰⁰

ADD TO CART

Volume Pricing	
Qty 1+	£370.60 each
Need More?	Request Quote

 Prices shown are exclusive of VAT/local taxes

Product Downloads

SPECIFICATIONS

General

Type:

Lens Accessory

Physical & Mechanical Properties

Inner Diameter (mm):

Optical Properties

VS Lens Wavelength Range:

Regulatory Compliance

Not Compliant RoHS 2015:


Not Compliant Reach 223:

[View](#) Certificate of Conformance:

PRODUCT DETAILS


- High Resolution Telecentric Lens for Measurement and Gauging
 - Up to 5 MegaPixels, 3.45µm Pixel Size Sensors
 - Up to 2/3", C-Mount Telecentric Lens
 - Magnification from 0.06X to 1X
- TECHSPEC® GoldTL™ Telecentric Lenses were designed specifically for machine vision and metrology applications. The unique focusable design allows for working distance adjustment, while still providing <0.2° telecentricity. These lenses also feature high resolutions, low distortions, and are available for ½" or 2/3" sensors. TECHSPEC® GoldTL™ Telecentric Lenses have a front filter thread for easy integration of [color filters](#), [polarizers](#) or other mounted components. Both the iris and focusing adjustment positions can be fixed by set screws to remain secure in high vibration environments.

TECHNICAL INFORMATION

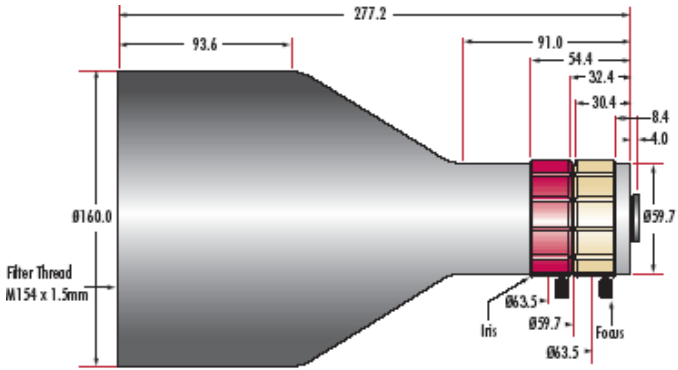


0.08X & 0.06X Telecentric Lens

Units: mm

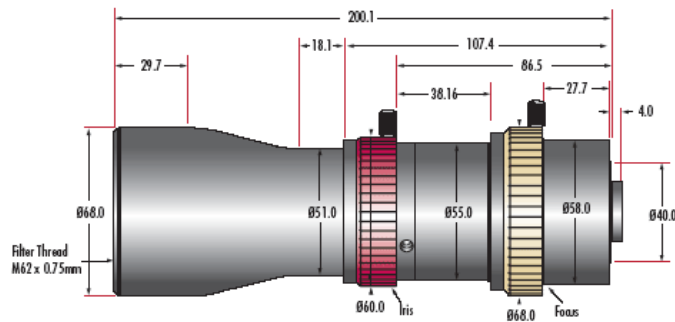


1X & 0.73X Telecentric Lenses

Units: mm

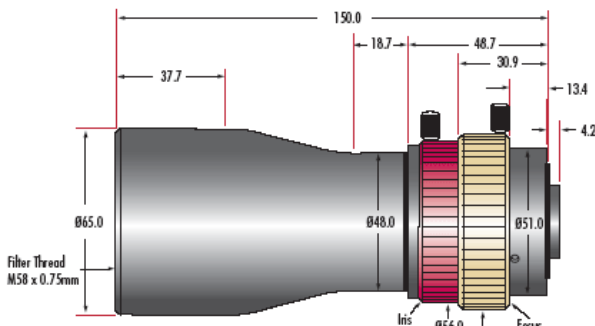

0.5X & 0.36X Telecentric Lenses

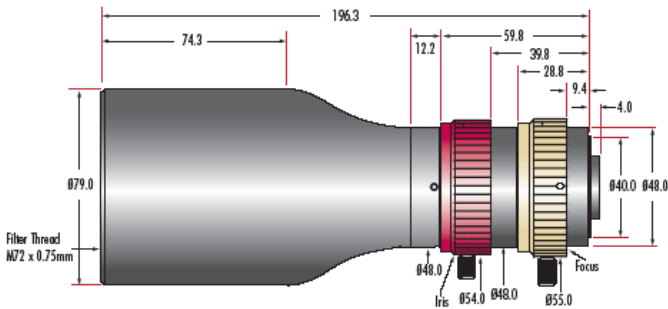

0.25X & 0.18X Telecentric Lenses

Units: mm

Stock No.	A	B	C	D	E	F	G
#56-024	88mm	16mm	34mm	94mm	120mm	101.6mm	50mm
#56-025	85mm	17.5mm	32.5mm	91mm	120mm	101.6mm	48.5mm
#56-026	103mm	—	39.5mm	107mm	103mm	90mm	55.5mm
#56-027	134mm	—	55mm	148mm	134mm	122mm	81mm

