


TECHSPEC[®] Penta Prism in C-Mount Cube

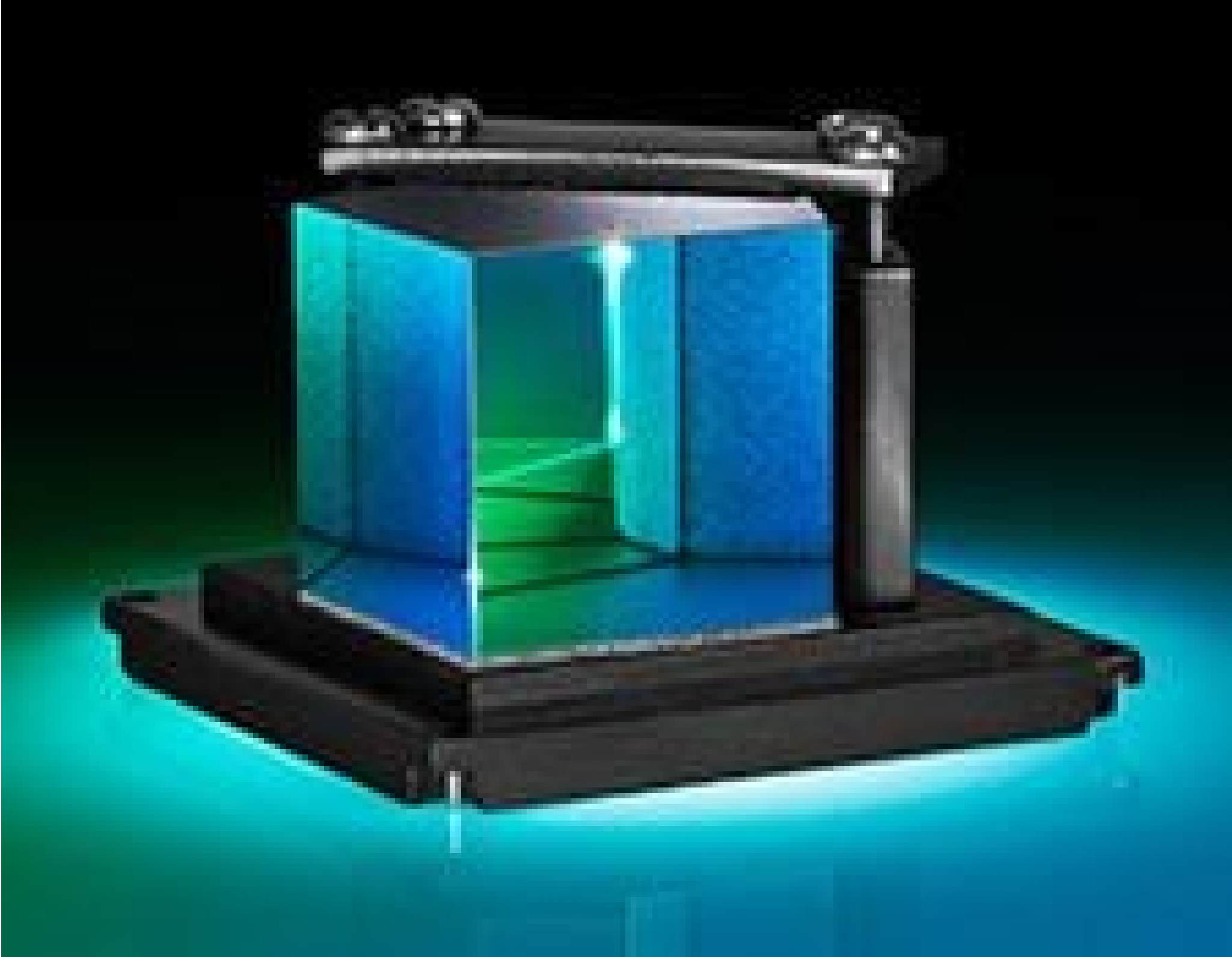

#53-401, Penta Prism in C-Mount Cube (Case Removed)



Stock #53-401 3-4 DAYS

-

1

+

£308.97

ADD TO CART

Qty 1-4

£308.97

Qty 5+

£272.59

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Coating:
MgF₂ & Aluminized

Substrate: ☐
[N-BK7](#)

Surface Quality: 60-40
Mounting Threads: 1/4-20
Type: Penta Prism
Extension Length (mm): 38.0
Dimensional Tolerance (mm): ±0.10
Angle Tolerance (arcmin): 3
Bevel: Protective bevel as needed
Construction: Housing: Black Anodized Aluminum
Length of Legs (mm): 25.00
Image Orientation: Right-Handed
Coating Specification: Entrance/Exit Faces: R _{avg} ≤1.75% @ 400 - 700nm Reflecting Surfaces: R _{avg} >85% @ 400 - 700nm w/Black Overpaint
Ray Deviation (°): 90
Wavelength Range (nm): 400 - 700
Surface Flatness (P-V): λ/4
Thread Type: C-Mount (1" x 32 TPI)

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View