 



SCHOTT BG50, 12.5mm Dia., 1mm Thick, Colored Glass Bandpass Filter

See More by [SCHOTT Optical Components](#)

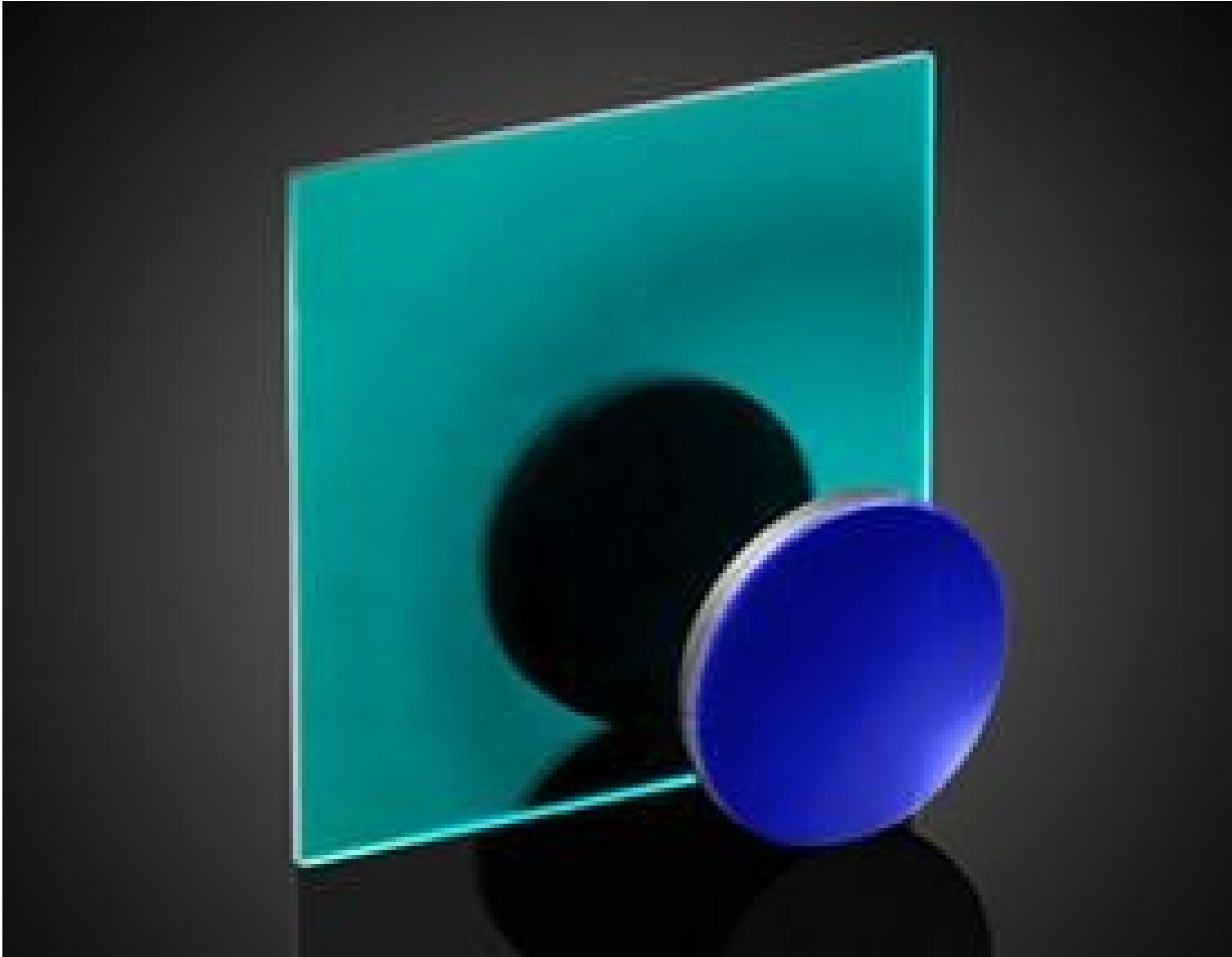

Stock **#16-364** 3-4 DAYS

[Additional Bandwidths](#)

-

1

+

£39.95

ADD TO CART

Qty 1-10
£39.95
Qty 11+
£34.85
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads
Diameter (mm): 12.50
Center Wavelength CWL (nm): 500.00

Density (g/cm³): 2.61
Glass/Filter Number: SCHOTT BG50
Coating: Uncoated
Color: Blue-Green
Index of Refraction n_d: 1.53
Surface Quality: 60-40
Transformation Temperature (°C): 452
Thickness (mm): 1.00 ±0.1
Type: Bandpass Filter
Wavelength: UV-VIS
Bevel: Protective as needed

Regulatory Compliance

Certificate of Conformance: View
--