 



SCHOTT BG7, 50mm Sq., 1mm Thick, Colored Glass Bandpass Filter

See More by [SCHOTT Optical Components](#)

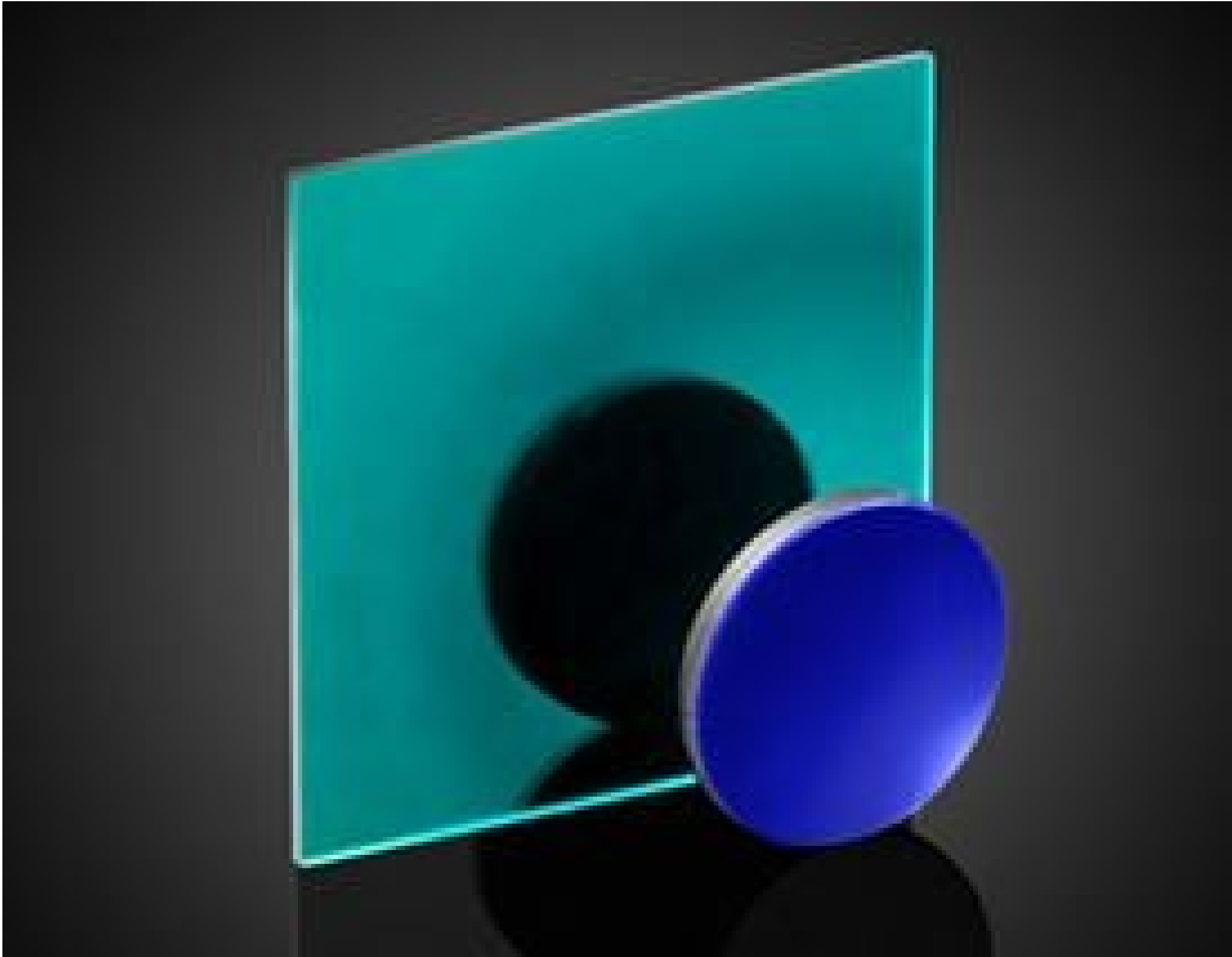

Stock **#14-406** ☐ In Stock

- 1 +

£74.80

ADD TO CART

Qty 1-10
£74.80
Qty 11+
£66.30
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Dimensions (mm):
50.0 x 50.0

Center Wavelength CWL (nm):
488.00

Density (g/cm³): 2.61
Glass/Filter Number: SCHOTT BG7
Length (mm): 50.00
Coating: Uncoated
Color: Deep Blue
Index of Refraction n_d: 1.52
Surface Quality: 60-40
Transformation Temperature (°C): 468
Thickness (mm): 1.00 ±0.1
Type: Bandpass Filter
Wavelength: UV-VIS
Width (mm): 50.00
Bevel: Protective as needed

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View