 



SCHOTT VG20, 12.5mm Dia., 3mm Thick, Colored Glass Bandpass Filter

See More by [SCHOTT Optical Components](#)

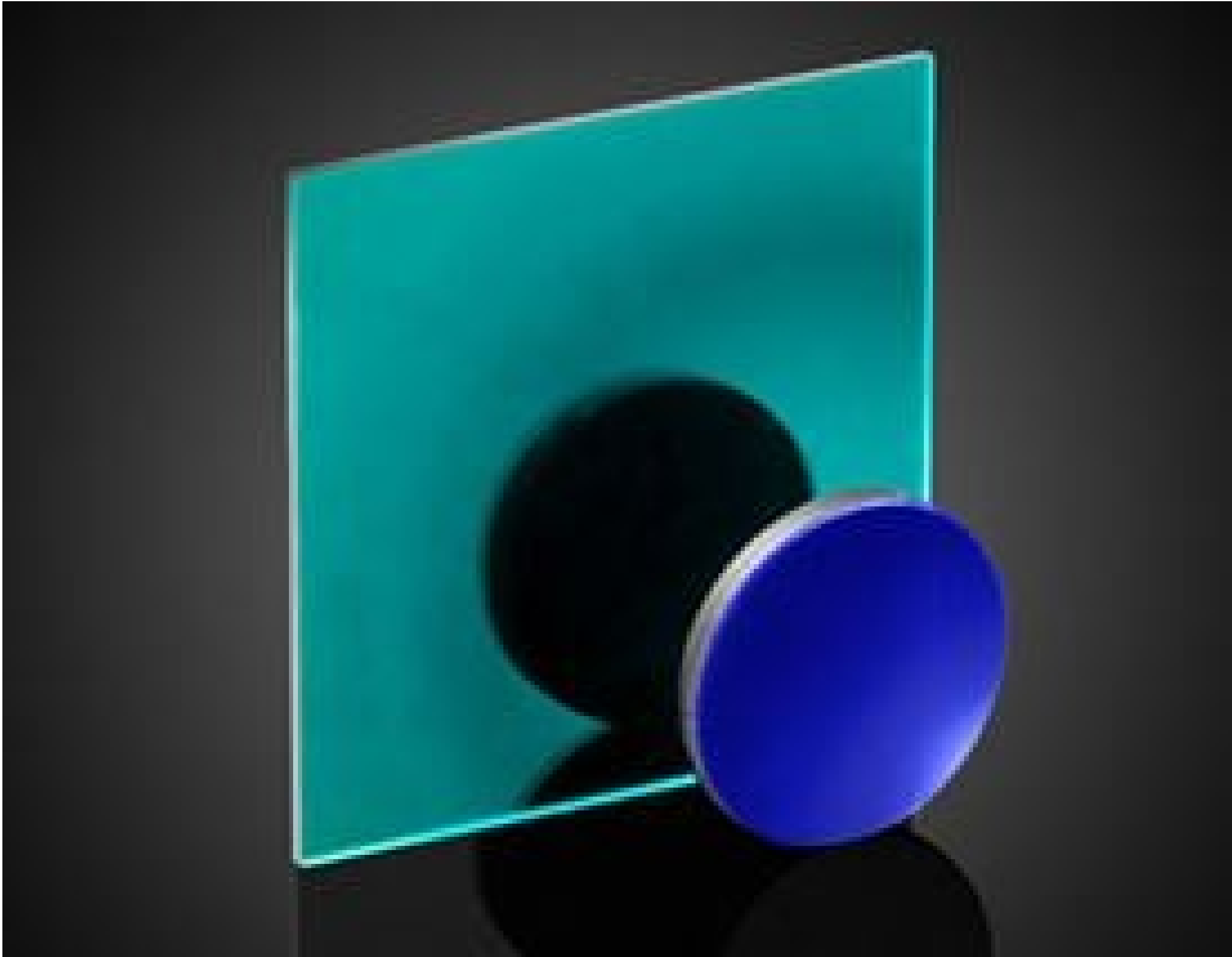

Stock **#16-397** 3-4 DAYS

[Additional Bandwidths](#)

-

1

+

£39.95

ADD TO CART

Qty 1-10
£39.95
Qty 11+
£34.85
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Diameter (mm):
12.50

Center Wavelength CWL (nm):
500.00

Density (g/cm³): 2.85
Glass/Filter Number: SCHOTT VG20
Coating: Uncoated
Color: Green
Index of Refraction n _d : 1.54
Surface Quality: 60-40
Transformation Temperature (°C): 390
Thickness (mm): 3.00 ±0.2
Type: Bandpass Filter
Wavelength: UV-VIS
Bevel: Protective as needed

Regulatory Compliance

Certificate of Conformance: View
