 



SCHOTT VG9, 50mm Sq., 2mm Thick, Colored Glass Bandpass Filter

See More by [SCHOTT Optical Components](#)

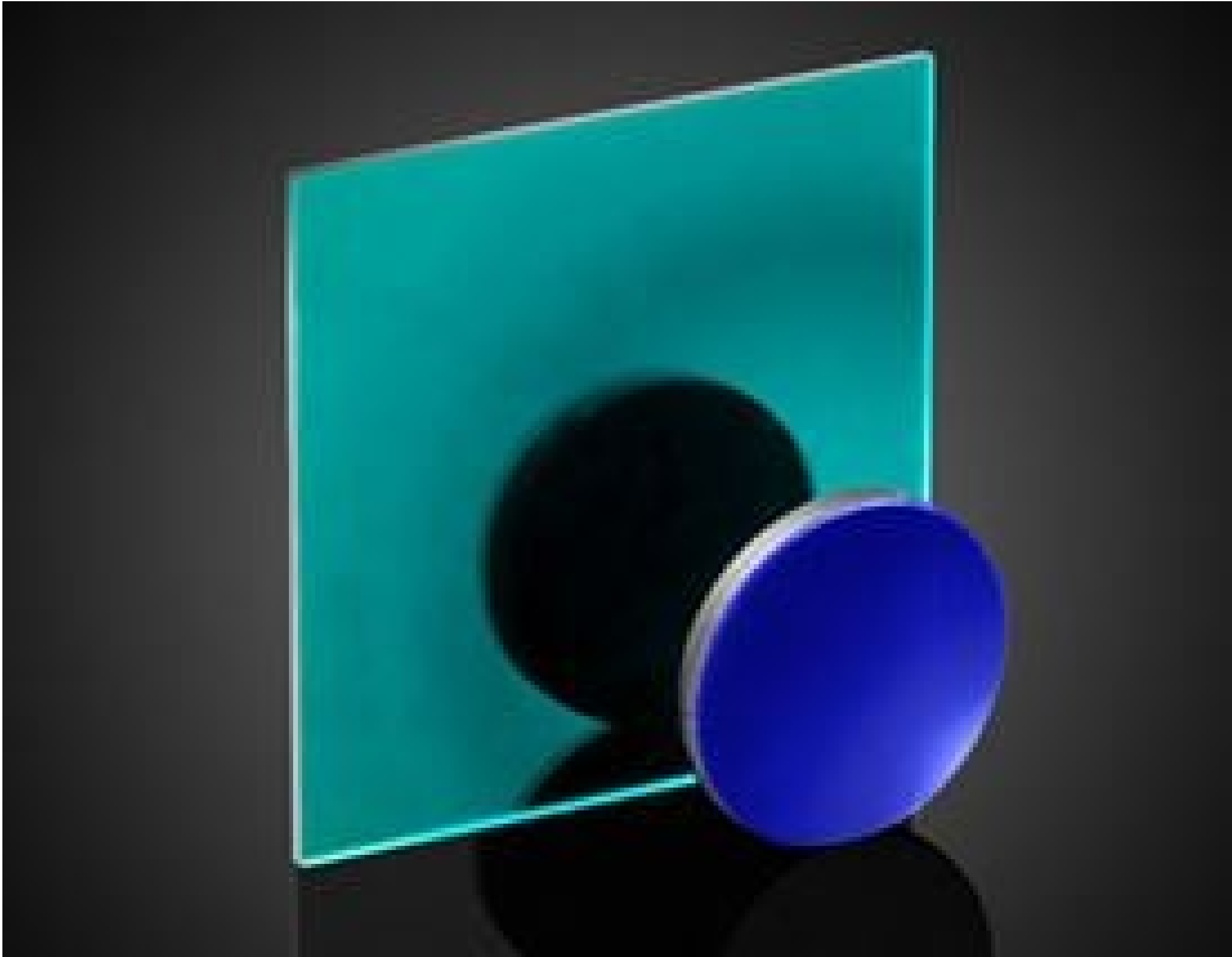

Stock #14-443 3-4 DAYS

- 1 +

£74.80

ADD TO CART

Qty 1-10

£74.80

Qty 11+

£66.30

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Dimensions (mm):
50.0 x 50.0

Center Wavelength CWL (nm):
525.00

Density (g/cm³): 2.87
Glass/Filter Number: SCHOTT VG9
Length (mm): 50.00
Coating: Uncoated
Color: Green
Index of Refraction n_d: 1.55
Surface Quality: 60-40
Transformation Temperature (°C): 462
Thickness (mm): 2.00 ±0.2
Type: Bandpass Filter
Wavelength: VIS
Width (mm): 50.00
Bevel: Protective as needed

Regulatory Compliance

RoHS 2015: Compliant
Reach 224: Compliant
Certificate of Conformance: View