 



Hoya U330 (UV) 25mm Square, Colored Glass Bandpass Filter

See More by [Hoya](#)

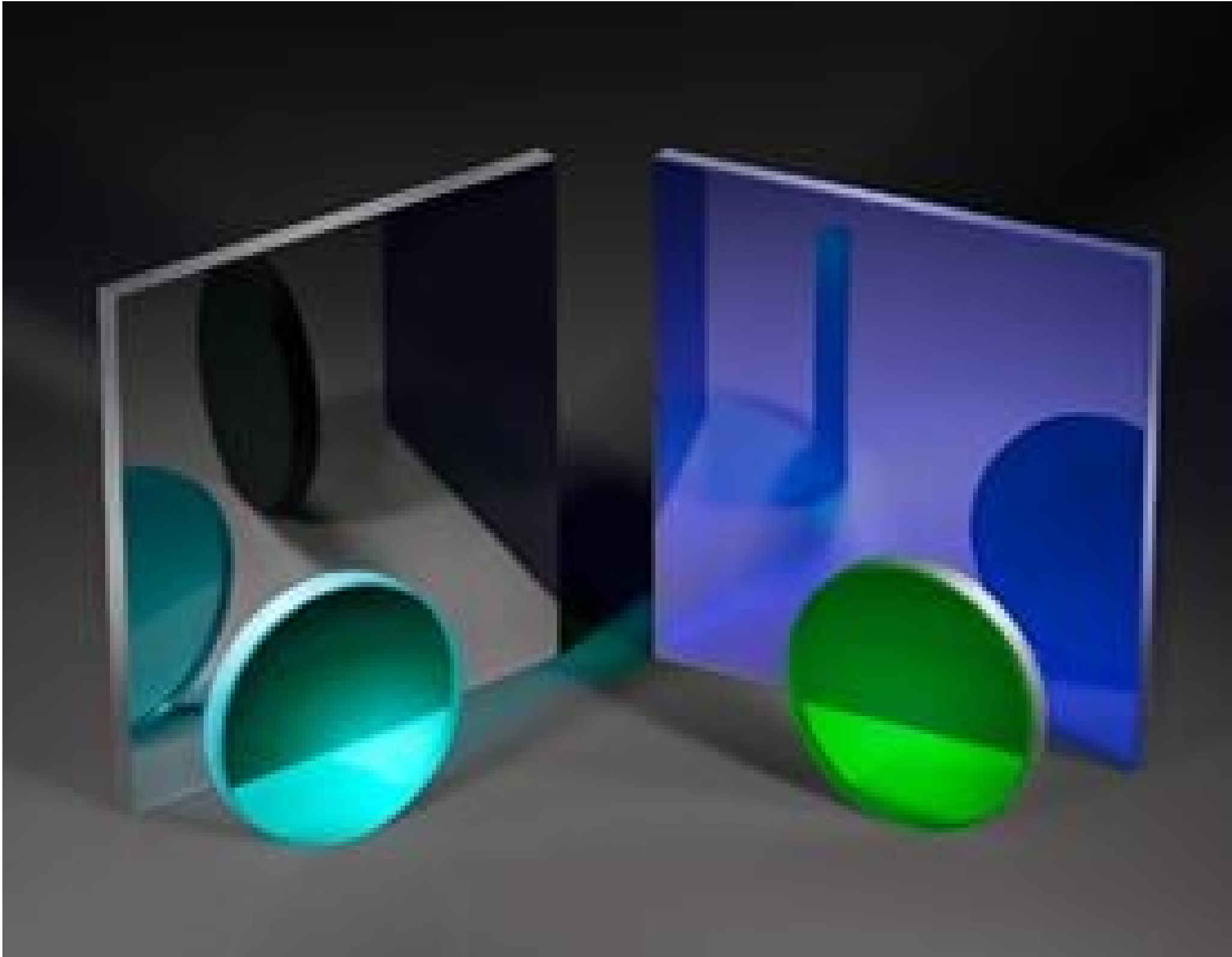

Stock **#46-083** 3-4 DAYS

-

1

+

£67.15

ADD TO CART

Qty 1-10

£67.15

Qty 11+

£59.50

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Dimensions (mm):
25.0 x 25.0

Center Wavelength CWL (nm):

330.00
Density (g/cm³): 2.78
Full Width-Half Max FWHM (nm): 140.00
Glass/Filter Number: Hoya U330
Substrate: ☐ Colored Glass
Length (mm): 25.00
Coating: Uncoated
Color: Black
Surface Quality: 60-40
Thickness (mm): 2.50
Thickness Tolerance (mm): ±0.2
Type: Bandpass Filter
Wavelength: UV
Width (mm): 25.00
Parallelism (arcmin): ≤1
Dimensional Tolerance (mm): +0/-0.25

Regulatory Compliance

RoHS 2015: Exempt
Reach 224: Compliant
Certificate of Conformance: View