


Variable Frequency Targets 5-200 lp/mm

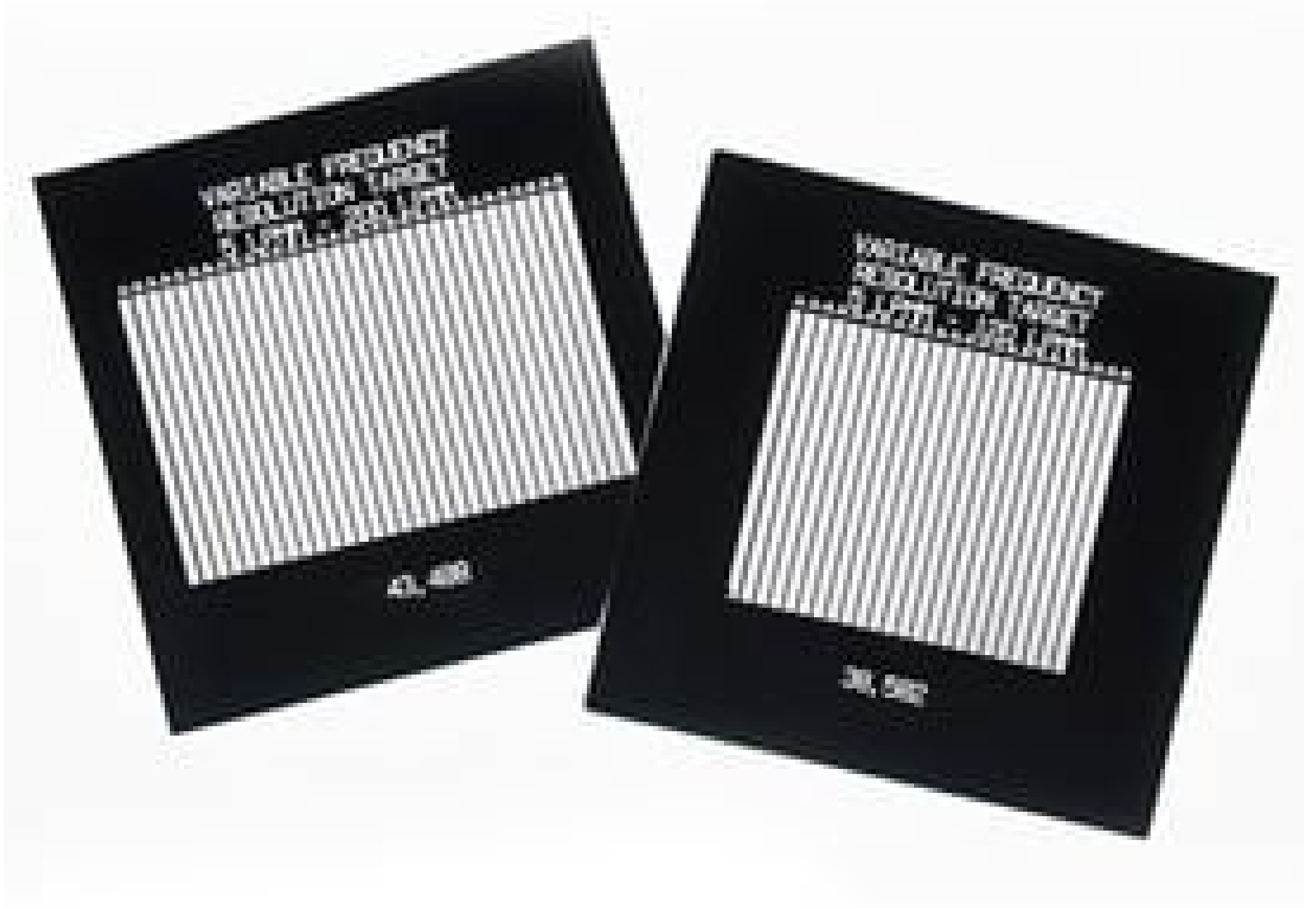

Stock **#43-488** CLEARANCE **1 In Stock**

£720^{.00}

ADD TO CART

Volume Pricing

Qty 1-4	£720.00 each
Qty 5+	£684.40 each
Need More?	Request Quote

i Prices shown are exclusive of VAT/local taxes

Product Downloads

Physical & Mechanical Properties

25.4 x 39.37 **Pattern Size (mm):**

2 x 2 **Dimensions (inches):**

1.50 **Thickness (mm):**

Beveled **Edges:**

0.00254 **Flatness (mm):**

Optical Properties

Coating:
Vacuum deposited durable chromium

Substrate:
Float Glass

Optical Density OD (Average):
≥3.0

Surface Quality:
40-10

Regulatory Compliance

RoHS 2015:
[Compliant](#)

Certificate of Conformance:
[View](#)

REACH 241:
[Compliant](#)

Product Details

- 5 lp/mm to 120 lp/mm or 5 lp/mm to 200 lp/mm
- 1mm Wide Step Size
- 5 lp/mm Step Increments
- Used to Calibrate Video Systems
- Inspect Unknown Resolutions

Variable frequency targets are excellent for evaluating resolution, field distortion, and parfocal stability.