


White, 0.312" LED Spot Light

See More by [Advanced Illumination](#)

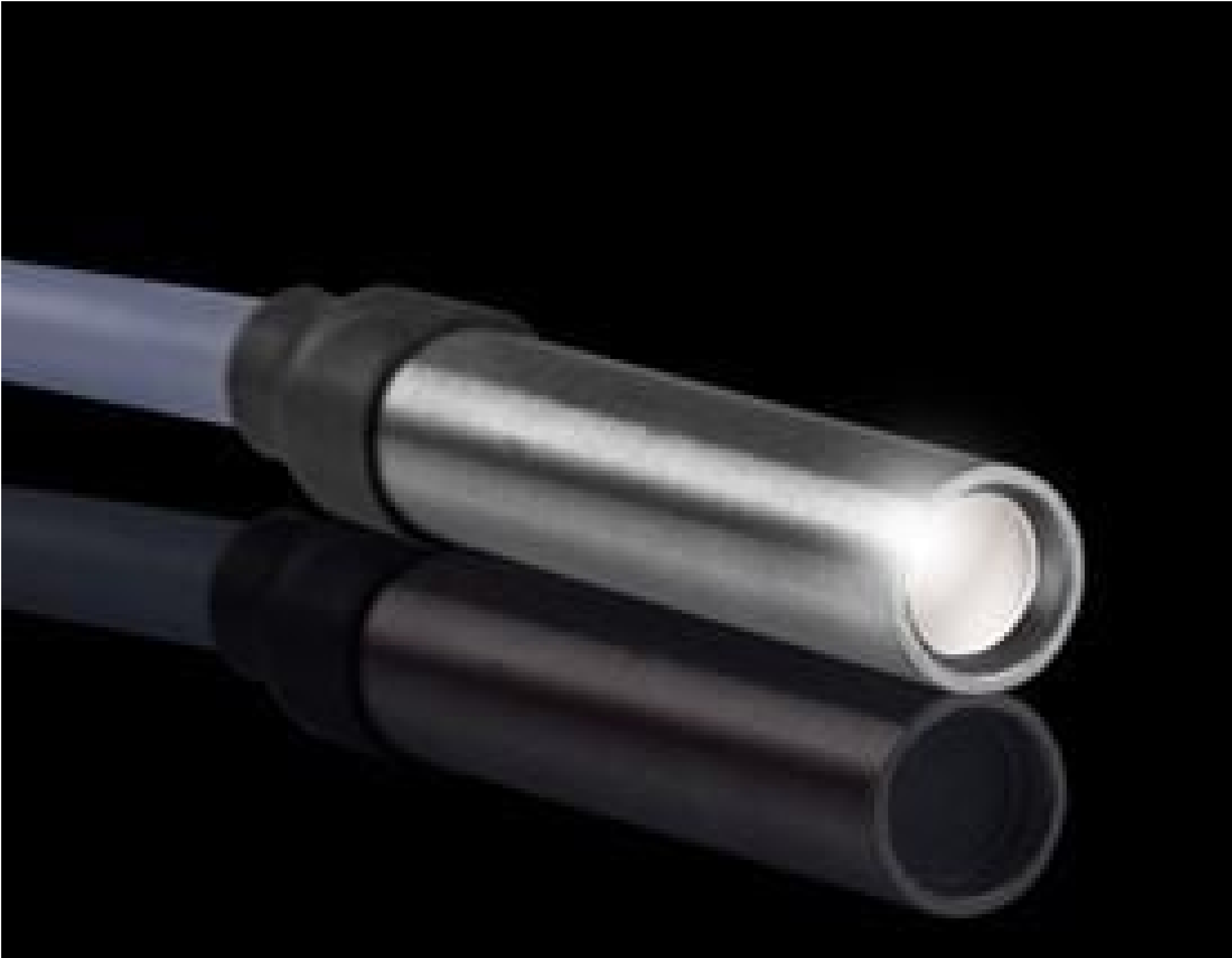

Stock **#87-541** [CONTACT US](#)

-

1

+

£163.20

ADD TO CART

Qty 1+

£163.20

Volume Pricing

[Request Quote](#)

 Prices shown are exclusive of VAT/local taxes

Note: This item requires accessories for use | [Learn More](#)

Get Product Downloads

Color:
White

Diameter (mm):
7.90

Fiber Bundle Diameter (inches):
¼

Model Number:

SL-4301A-WHI-IC
Length (mm): 38.10
Outer Diameter (inches): 0.312 nominal, 0.314 max
LED Lifetime (hours): 50,000
Power Supply: Power Supply Required and Sold Separately. USA: #66-855 Europe: #66-855 Japan: #66-855 Korea: #33-773 China: #66-855
Length of Cable (m): 1.5
Type of Illumination: LED Illuminator
Manufacturer: Advanced Illumination
Geometry: Spot Light
Illumination Mode: Constant

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Contains SVHC(s)